



D-Sub Full Metal, Top cable entry

TECHNICAL SPECIFICATIONS



Material:	Zinc, Nickel Plated
Operating Temperature:	-40°C to +120°C
Cable Entry:	Top Entry
Strain relief:	Clamp + Metalized Insert
Thumbscrews:	UNC 4-40 (Standard) M2,5 or M3 on request
Cable O.D.:	Up to 18,0mm (Standard)

Features:

- 360° EMI Shielding
- Extra Large Cable entry
- Available in sizes 25 and 37, other sizes on request
- Quick assembly
- Pre-mounted locking screws
- Supports all types of cables
- Suitable for any common D-Sub connector

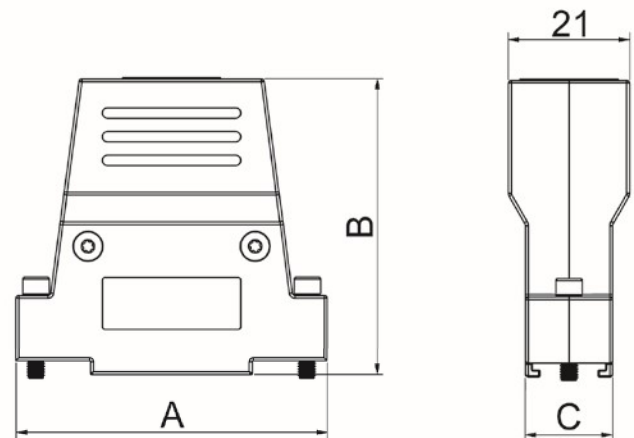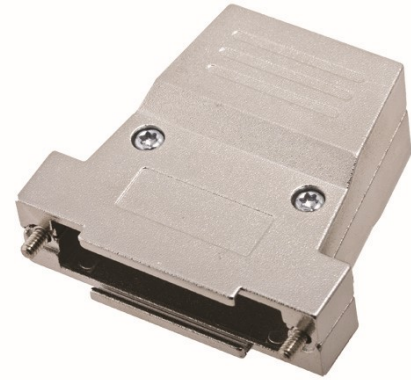

Grommet Sizes:

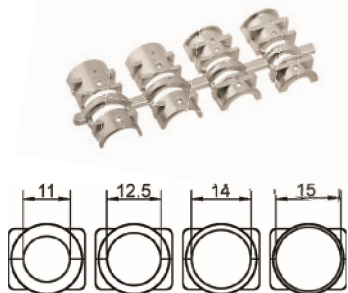 

Size 15-25-37

Size DTXL	Dim A	Dim B	Dim C
15-way	40,8	51,5	14,9
25-way	54,1	51,5	14,9
37-way	70,7	61,5	15,1

Ordering information:

Size:	P/N - Kitted:	Product Code:
15-way	On request	
25-way	6560-0703-33	DTXL25-HI-SJS-T-K
37-way	6560-0703-34	DTXL37-HI-SJS-T-K

Size:	P/N - BULK:	Product Code:
15-way	On request	
25-way	6561-0703-33	DTXL25-HI-SJS-T
37-way	6561-0703-34	DTXL37-HI-SJS-T

