

# Tapplock one+

## Multi-Functional Utility Lock



### Cutting-Edge Fingerprint Technology

Tapplock's advanced fingerprint technology identifies the access user to 99.999% accuracy and grants access in under 0.8 seconds. Stores up to 500 fingerprints for multiple users per lock.



### Unbreakable Durability

Tapplock one+ is equipped with reinforced stainless steel shackle and double layered housing body. It features our proprietary anti-shim technologies. The absence of a keyhole also eliminates risks of being picked.



### Rated IP67 waterproof and weather-proof

Rated IP67 waterproof and weather-proof. Fully functional between -20C and 65C (-4F and 149F).



### 3 Ways To Unlock

Fingerprint, Bluetooth, and backup Morse Code unlocking by setting custom long / short combinations.



### Powerful Rechargeable Battery


1-year use (or 3,500 unlocks) per 2-hour charge time. Check remaining power using the Tapplock app.



# Tapplock one+ Dimensions

## Weight

300g/0.66lbs (without package)

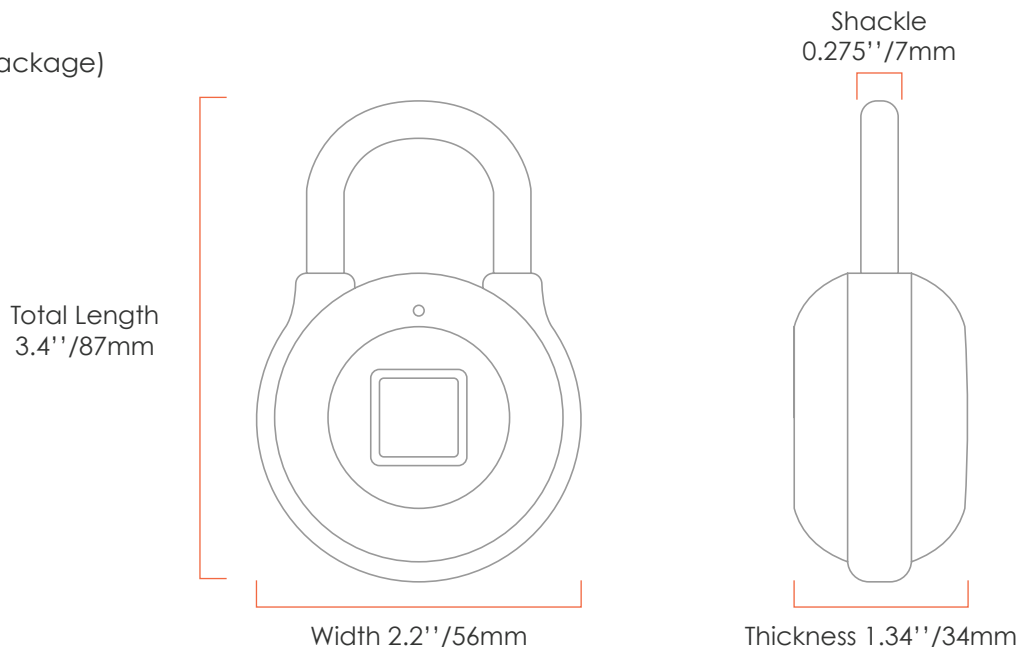

# Technical Specifications

Item	Description
Bluetooth	Bluetooth 4.0
Fingerprint Sensor	FPC1020AM
Fingerprint Storage	Up to 500 fingerprints
Fingerprint Sensor Wear-And-Tear	>10 million times at 0.6N
Ideal Operating Temperature & Humidity	-10°C~40°C, 20%-85%
Operating Temperature & Humidity	-20°C~65°C, 10%-90%
Charging Voltage & Current	5V, 1A(Max)
Battery Life	1-year battery life per full charge
App Compatibility	iOS 8.0 or later/ Andriod 4.4.2 or later
International Standard Compliance	FCC: Part 15C & Part 15B, CE: EN300328V.2.1.1; EN301489-1;EN301489-17; EN62479;EN60950 IC: RSS 210,ICES-003 Proposition 65 Compliant ISO9001