


TECHNICAL SPECIFICATIONS

D-Sub Hood:

Material: Zinc, Nickel Plated
 Operating Temperature: -45°C to + 105°C
 Cable Entry: Side Entry
 Thumbscrews: UNC 4-40 (Standard)
 Cable O.D:
 9-Way: Up to 9,5mm
 15-Way: Up to 12,5mm
 25-Way: Up to 12,5mm
 37-Way: Up to 15,5mm

Female D-Sub Solder Cup:

Insulator: PBT, Black, UL94 V-0
 Shell: Steel, Tin Plated
 Contact pins: Copper Alloy
 Stamped & Formed Pins: Class 3, 100 inserts min.
 Machined Contact Pins: Class 1, 500 inserts min.
 Contact Plating: Selective Gold over Nickel
 Operating Temperature: -55°C to +105°C
 Withstanding voltage: 1000V for 1 minute
 Insulator resistance: 1000MΩ min.

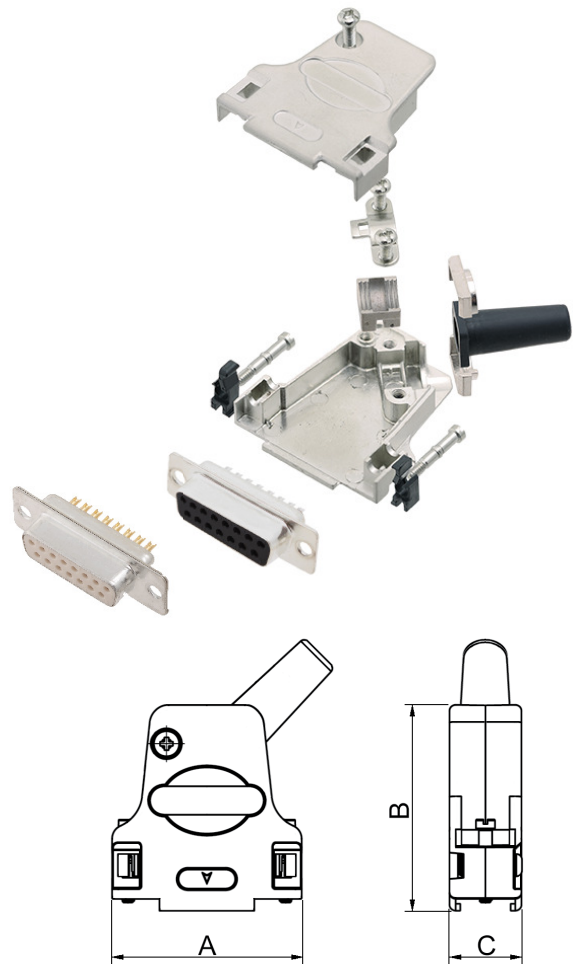

Features:

- Available in sizes 9-15-25-37
- Excellent EMI Shielding
- Re-openable
- Spring-Clip mounted Jackscrews

| Size D45ZF | Dim A | Dim B | Dim C |
|------------|-------|-------|-------|
| 9-way | 31,6 | 39,5 | 15,2 |
| 15-way | 40,0 | 41,0 | 15,2 |
| 25-way | 53,7 | 47,5 | 15,2 |
| 37-way | 70,2 | 48,0 | 15,2 |

Ordering information - Black Insulator:

| Size: | P/N - Kitted: | Class 3 - 100 inserts min. |
|--------|---------------|----------------------------|
| 9-way | 6355-0046-11 | D45ZF09-DBS-K |
| 15-way | 6355-0046-12 | D45ZF15-DBS-K |
| 25-way | 6355-0046-13 | D45ZF25-DBS-K |
| 37-way | 6355-0046-14 | D45ZF37-DBS-K |

| Size: | P/N - Kitted: | Class 1 - 500 inserts min. |
|--------|---------------|----------------------------|
| 9-way | 6355-0047-11 | D45ZF09-DMS-K |
| 15-way | 6355-0047-12 | D45ZF15-DMS-K |
| 25-way | 6355-0047-13 | D45ZF25-DMS-K |
| 37-way | 6355-0047-14 | D45ZF37-DMS-K |

Ordering information - White Insulator:

| Size: | P/N - Kitted: | Class 3 - 100 inserts min. |
|--------|---------------|----------------------------|
| 9-way | 6355-8046-11 | D45ZF09-DBS-W-K |
| 15-way | 6355-8046-12 | D45ZF15-DBS-W-K |
| 25-way | 6355-8046-13 | D45ZF25-DBS-W-K |
| 37-way | 6355-8046-14 | D45ZF37-DBS-W-K |

| Size: | P/N - Kitted: | Class 1 - 500 inserts min. |
|--------|---------------|----------------------------|
| 9-way | 6355-8047-11 | D45ZF09-DMS-W-K |
| 15-way | 6355-8047-12 | D45ZF15-DMS-W-K |
| 25-way | 6355-8047-13 | D45ZF25-DMS-W-K |
| 37-way | 6355-8047-14 | D45ZF37-DMS-W-K |

