

Data Sheet


TECHNICAL SPECIFICATIONS

D-Sub Hood:

| | |
|------------------------|--|
| Material: | Zinc, Nickel Plated |
| Operating Temperature: | -45°C to + 105°C |
| Cable Entry: | Side Entry |
| Thumbscrews: | UNC 4-40 (Standard) |
| Cable O.D: | 9-Way: Up to 9,5mm 15-Way: Up to 12,5mm 25-Way: Up to 12,5mm 37-Way: Up to 15,5mm |

D-Sub High Density:

| | |
|------------------------|----------------------------|
| Insulator: | PBT, Black, UL94 V-0 |
| Shell: | Stamped Steel, Tin Plated |
| Contact pins: | Copper Alloy |
| Stamped & Formed pins: | 100 inserts min |
| Contacts Plating: | Selective Gold over Nickel |
| Operating Temperature: | -55°C to +105°C |
| Withstanding voltage: | 500V for 1 minute |
| Insulator resistance: | 500MΩ min |

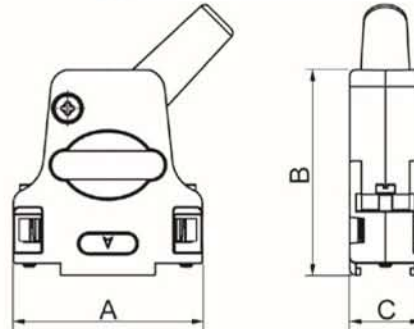

| Size D45ZF | Dim A | Dim B | Dim C |
|------------|-------|-------|-------|
| 9-way | 31,6 | 39,5 | 15,2 |
| 15-way | 40,0 | 41,0 | 15,2 |
| 25-way | 53,7 | 47,5 | 15,2 |
| 37-way | 70,2 | 48,0 | 15,2 |