



► (RTS) Surface Type

RT-K02 Si+Si.SKP5

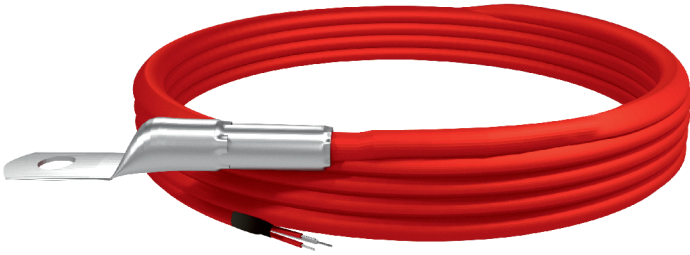

► (RTS) Surface Type

RT-K02.SKP5

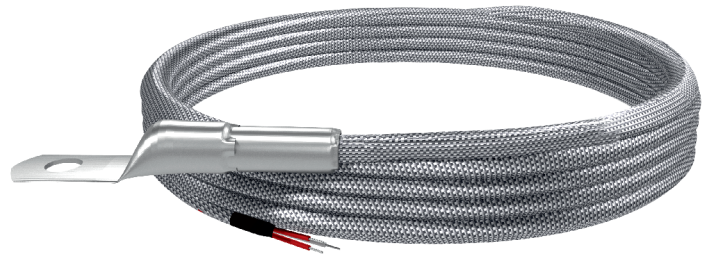

Max. operating temperature : -50 °C / +200 °C

Standard cable types : Si + Si

Standard cable length (K) : 2m

Sensor type : DIN/EN60751 Class "B" 1xPT-100

Max. operating temperature : -50 °C / +400 °C

Standard cable types : Fiber glass + braided wire

Standard cable length (K) : 2m

Sensor type : DIN/EN60751 Class "B" 1xPT-100