

## Data Sheet

### TECHNICAL SPECIFICATIONS


**Materials:**

Unshielded Hood: UL-recognised plastic material  
 Colour: Grey

Shielded Hood: UL-recognised plastic material  
 Plating: Nickel over Copper



Operating Temperature: -30°C to +90°C

Thumbscrews: UNC 4-40 (Standard)

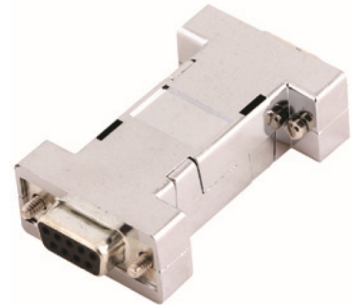

**Features:**

- Available in sizes 9 and 25 (15 on request)
- Available in EMI-shielded and unshielded version
- Delivered complete with wires and Sub-D
- Pre-wired connectors on request

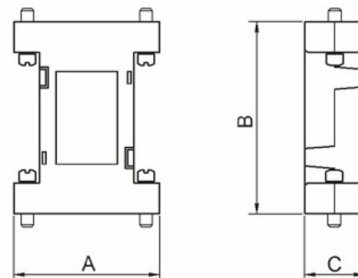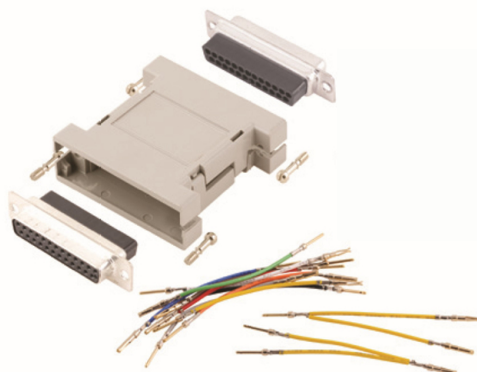

Size GA	Dim A	Dim B	Dim C
9-way	33,2	62,0	16,5
15-way	41,0	62,0	16,5
25-way	56,0	62,0	16,5