



Cat.8.1 S/FTP Patch Cable

Technical Features

Premium Cat.8.1 Round Patch Cord

Cat.8.1 Class I ISO11801 channel tested

Application: 40G Base-T, PoE+, PoE++

Wire: 4 x 2 x 26/7 AWG bare copper


Shielding: overall screen, pairs in metal foil (PiMF)

Cable: LSZH sheath, 6.2 mm cable OD

Plug: RJ45, shielded, gold plated contacts

Color of cable: Blue

Technical Drawing

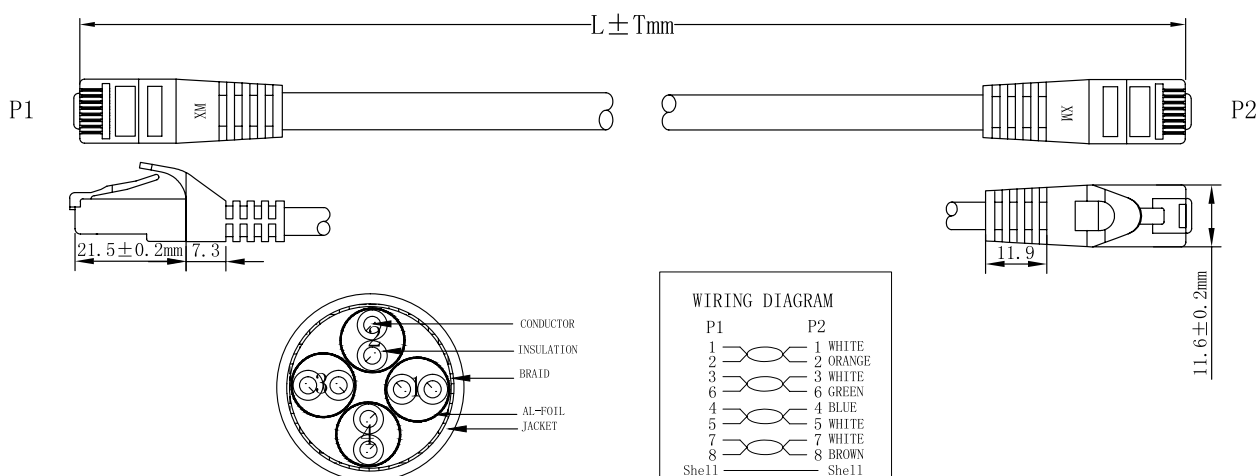

Art-No.	Cable Length	EAN Code
CQ8026S	0.5 m	4052792051995
CQ8036S	1 m	4052792052008
CQ8046S	1.5 m	4052792052015
CQ8056S	2 m	4052792052022
CQ8066S	3 m	4052792052039
CQ8076S	5 m	4052792052046
CQ8096S	10 m	4052792052053
CQ8106S	15 m	4052792052169
CQ8116S	20 m	4052792070491

Package Content

1x Cat.8.1 S/FTP Patch Cable

Packaging Information

Art-No.	Packing Dimension	Packing Weight	Carton Dimension	Carton Q'ty	Carton Weight
CQ8026S	180 x 15 x 130 mm	0.034 kg	400 x 300 x 300 mm	200 pcs	7.6 kg
CQ8036S	180 x 11 x 180 mm	0.054 kg	400 x 300 x 300 mm	140 pcs	8.4 kg
CQ8046S	195 x 15 x 195 mm	0.075 kg	400 x 300 x 300 mm	100 pcs	8.1 kg
CQ8056S	185 x 16 x 185 mm	0.093 kg	400 x 300 x 300 mm	80 pcs	8.2 kg
CQ8066S	185 x 20 x 185 mm	0.132 kg	400 x 300 x 300 mm	60 pcs	8.6 kg
CQ8076S	185 x 23 x 185 mm	0.210 kg	400 x 300 x 300 mm	40 pcs	9.1 kg
CQ8096S	190 x 40 x 190 mm	0.395 kg	400 x 300 x 300 mm	25 pcs	11.2 kg
CQ8106S	220 x 45 x 220 mm	0.601 kg	400 x 300 x 300 mm	18 pcs	11.5 kg
CQ8116S	220 x 40 x 260 mm	0.667 kg	400 x 300 x 300 mm	18 pcs	12.7 kg



www.2direct.de



Made in China

*The specifications and pictures are subject to change without prior notice.
*All trade names referenced are the registered trademarks of their respective owners.