

**Industrial Ethernet
IE-PS-M12X-P-FH****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com



M12 X type cat. 6A plug can be assembled on-site with
quick connection system

General ordering data

Type	IE-PS-M12X-P-FH
Order No.	1324020000
Version	Plugs prefabricated to customer spec., M12, Insulation displacement technology, Cat.6 _A / Class E _A (ISO/IEC 11801 2010), IP67
GTIN (EAN)	4050118127782
Qty.	10 pc(s).

Industrial Ethernet IE-PS-M12X-P-FH

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

Technical data

Dimensions and weights

Net weight	33.95 g
------------	---------

Temperatures

Operating temperature, max.	85 °C	Operating temperature, min.	-40 °C
Operating temperature	-40 °C...85 °C	Storage temperature	
Installation temperature			

Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
------------	----------------

General Info

Connection 1	M12	Connection 2	Insulation displacement technology
Wiring	EIA/TIA T568 A, EIA/TIA T568 B	Housing main material	Zinc diecast
Insulation cross-section, max.	1.6 mm	Category	Cat.6A / Class EA (ISO/IEC 11801 2010)
Connection thread	M12	Contact material	Brass
Contact surface	Gold-plated	Connection diameter, solid	0.4...0.64 mm
Conductor connection cross-section, solid (AWG)	AWG 24...AWG 22	Connection diameter, flexible	0.48...0.76 mm
Conductor connection cross-section, flexible (AWG)	AWG 26...AWG 22	Sheath diameter, min.	5 mm
Sheath diameter, max.	9.7 mm	Contact holder materials	PA
Shielding	360°; all-round enclosure	Protection degree	IP67
Plugging cycles	≥ 100		

Electrical properties

Current-carrying capacity at 50 °C	0.5 A @ 40 °C	Insulation strength	100 MΩ
PoE / PoE+	conforming to IEEE 802.3at	Rated voltage	48 V

Standards

Fire safety for railway vehicles	DIN EN 45545-2	Connector standard	IEC 61076-2-109
Certificate no. (cULus)	E316369		

Classifications

ETIM 6.0	EC002062	eClass 6.2	27-25-05-04
eClass 7.1	27-25-05-04	eClass 8.1	19-17-01-25
eClass 9.0	27-44-01-02	eClass 9.1	27-44-01-03

Industrial Ethernet IE-PS-M12X-P-FH

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

Technical data

Approvals

Approvals



ROHS

Conform

Downloads


Approval/Certificate/Document of Conformity	DUXR.E316369 Certificat CC Link IE Field M12-X
Brochure/Catalogue	CAT 9 IETH 15/16 EN CAT 8 SAI 15/16 EN MB FREECONTACT EN FL FIELDWIRING EN PI PROFINET CABLING EN
User Documentation	MAN IE GUIDE DE MAN IE GUIDE EN Manual

Industrial Ethernet IE-PS-M12X-P-FH

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

Drawings

Dimensioned drawing

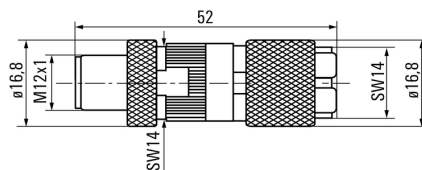

Pinning

