

SAI-Y-3/3 M8-M8 U**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

Similar to illustration

Individual cable lengths are often required nowadays. In order to meet these demands, Weidmüller offers a wide range of plug-in connectors for custom assembly. Y-distributors are used to bundle and distribute multiple signals to save space.

General ordering data

Type	SAI-Y-3/3 M8-M8 U
Order No.	1550620000
Version	Y connector, M8 / M8
GTIN (EAN)	4050118357141
Qty.	1 pc(s).

SAI-Y-3/3 M8-M8 U

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

Technical data

Dimensions and weights

Net weight	17 g
------------	------

Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
------------	----------------

Connection data

Group outlet - plug-in connector	M8 pin	Single outlet 1 - plug-in connector	M8 socket
Single outlet 2 - plug-in connector	M8 socket	Tightening torque	M8: 0.5 - 0.6 Nm

General data

Coding	M8 = none	Conductor O.D.	-
Connection thread	M8 / M8	Contact surface	Au (Gold)
Housing main material	PUR	No. of poles	3
Plugging cycles	≥ 100	Pollution severity	3
Protection degree	IP67	Rated current	4 A
Rated voltage	24 V	Shield connection	No
Temperature range of housing	-25...+85 °C		

Classifications

ETIM 5.0	EC002641	ETIM 6.0	EC002925
eClass 6.2	27-26-07-08	eClass 7.1	27-44-03-12
eClass 8.1	27-44-03-12	eClass 9.0	27-44-01-06
eClass 9.1	27-44-01-06		

Approvals

ROHS	Conform
------	---------

Downloads


Brochure/Catalogue	FL FIELDWIRING EN
--------------------	-----------------------------------

SAI-Y-3/3 M8-M8 U

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

Drawings

Dimensioned drawing

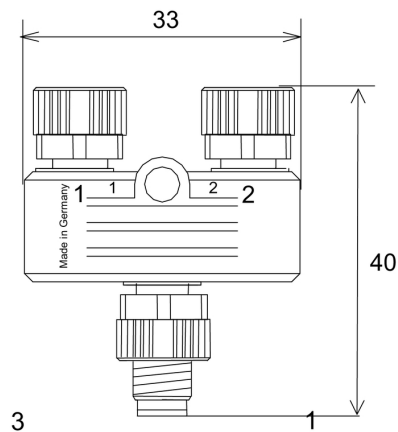

Wiring diagram

