

THM
THM MT30X 25.4/50.8 SI**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16


D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

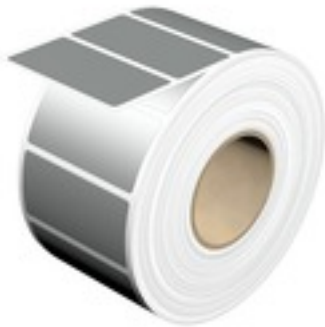

Similar to illustration

The THM labels offer brilliant printing quality thanks to the thermal transfer technology. Different materials and the user-friendly printing system under Windows optimise every marking effort.

- High-quality polyester labels in various colours or inexpensive paper labels are available
- Labels are automatically positioned in the printer for perfectly centred prints on each label.

General ordering data

Type	THM MT30X 25.4/50.8 SI
Order No.	1378120000
Version	THM, Device markers, 50.8 x 25.4 mm, silver
GTIN (EAN)	4050118179590
Qty.	1 pc(s).
compatible printer	2430920000 2448870000

THM

THM MT30X 25.4/50.8 SI

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
www.weidmueller.com

Technical data

Dimensions and weights

Width	25.4 mm	Width (inches)	1 inch
Height	50.8 mm	Height (inches)	2 inch
Depth	0.08 mm	Depth (inches)	0.003 inch
Net weight	457 g		

General data

Adhesive	Acrylate adhesive	Approval acc. to UL 969	Yes
Colour	silver	Halogen	No
Material	Polyester	Number per roll	2,000
Operating temperature range	-40...150 °C	Printing method	Thermotransfer
UL 94 flammability rating	V-0	Version	Self-adhesive, halogen-free
Width	25.4 mm		

Classifications

ETIM 5.0	EC001288	ETIM 6.0	EC001288
eClass 6.2	27-14-91-29	eClass 7.1	27-14-91-29
eClass 8.1	27-14-91-29	eClass 9.0	27-40-06-29
eClass 9.1	27-40-06-29		

Approvals

ROHS	Conform
------	---------

Downloads

Engineering Data	EPLAN, WSCAD
Engineering Data	STEP
Software	M-Print PRO configuration file

Data sheet

THM
THM MT30X 25.4/50.8 SI

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

Drawings