

**HS-FR 12.7-25.4/25 MM W****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16

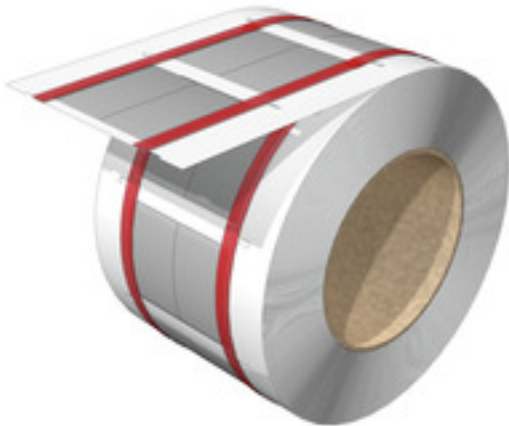
D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

**MultiMark**

With MultiMark you have a fast and reliable marking system at your disposal to enable virtually any kind of marking. Connectors, conductors, cables or devices – the MultiMark product family offers a well-structured, practical range of markers which can be used in combination with our advanced M-Print® PRO configuration software for all areas of use.

**Your benefits with MultiMark**

- Compact, practice-oriented range of products
- Quickly printed and assembled
- Reliable identification of your connections
- Excellent material properties

**General ordering data**

Type	HS-FR 12.7-25.4/25 MM W
Order No.	<a href="#">262170000</a>
Version	Conductor and cable markers, 12.7 - 25.4 mm, 24.9 x 40.5 mm, white
GTIN (EAN)	4050118625349
Qty.	600 pc(s).
compatible printer	<a href="#">243092000</a>

**HS-FR 12.7-25.4/25 MM W****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

**Technical data****Dimensions and weights**

Width	40.5 mm	Width (inches)	1.594 inch
Height	24.9 mm	Height (inches)	0.98 inch
Depth	0.77 mm	Depth (inches)	0.03 inch
Net weight	1.6 g		

**General data**

Colour	white	Halogen	No
Material	Polyolefine	Operating temperature range	-55... 125 °C
Size of labelling field	40.5 x 24.9 mm	Width	40.5 mm

**Conductor and cable markers**

Conductor O.D.	12.7 - 25.4 mm	Conductor O.D., max.	25.4 mm
Conductor O.D., min.	12.7 mm	Conductor cross-section, max.	120 mm <sup>2</sup>
Conductor cross-section, min.	35 mm <sup>2</sup>	Halogen	No
Rate of shrinkage	2:1	Recommended shrinking temperature	90 °C
Wire connection cross section AWG, max.	AWG 4/0	Wire connection cross section AWG, min.	AWG 2

**Classifications**

ETIM 5.0	EC001530	ETIM 6.0	EC001530
eClass 6.2	27-40-04-01	eClass 9.0	27-40-04-01
eClass 9.1	27-40-04-01		

**Approvals**

ROHS	Conform
------	---------

**Data sheet**

**HS-FR 12.7-25.4/25 MM W**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 16  
D-32758 Detmold  
Germany  
Fon: +49 5231 14-0  
Fax: +49 5231 14-292083  
[www.weidmueller.com](http://www.weidmueller.com)

**Drawings**

