

**THM**  
**THM ET S7 1500-13 TU****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16


D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

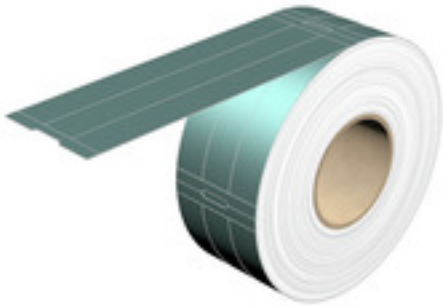

THM ET S7 non-adhesive, roll-packaged labels are used to label the SIMATIC ET 200S, S7-300 and S7-400 modules from Siemens.

- The M-Print® PRO software can be used to individually print the THM ET S7 labels with a THM printer.
- Labels can be easily separated
- The THM Plus S printer ensures highly-resistant printing

**General ordering data**

|                    |                                                        |
|--------------------|--------------------------------------------------------|
| Type               | THM ET S7 1500-13 TU                                   |
| Order No.          | <a href="#">2093010000</a>                             |
| Version            | THM, Device markers, 108.8 x 13 mm, Siemens, Turquoise |
| GTIN (EAN)         | 4050118421897                                          |
| Qty.               | 500 pc(s).                                             |
| compatible printer | <a href="#">2430920000</a> <a href="#">2448870000</a>  |

# THM

## THM ET S7 1500-13 TU

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 14-0  
 Fax: +49 5231 14-292083  
[www.weidmueller.com](http://www.weidmueller.com)

## Technical data

### Dimensions and weights

|            |          |                 |            |
|------------|----------|-----------------|------------|
| Width      | 13 mm    | Width (inches)  | 0.512 inch |
| Height     | 108.8 mm | Height (inches) | 4.283 inch |
| Depth      | 0.08 mm  | Depth (inches)  | 0.003 inch |
| Net weight | 0.4 g    |                 |            |

### General data

|                             |               |                         |                |
|-----------------------------|---------------|-------------------------|----------------|
| Application/manufacture     | Siemens       | Approval acc. to UL 969 | No             |
| Colour                      | Turquoise     | Halogen                 | No             |
| Material                    | Polypropylene | Number per roll         | 500            |
| Operating temperature range | -50...100 °C  | Printing method         | Thermotransfer |
| UL 94 flammability rating   | HB            | Version                 | halogen-free   |
| Width                       | 13 mm         |                         |                |

### Classifications

|            |             |            |             |
|------------|-------------|------------|-------------|
| ETIM 5.0   | EC001288    | ETIM 6.0   | EC001288    |
| eClass 6.2 | 27-14-91-29 | eClass 9.0 | 27-40-06-29 |
| eClass 9.1 | 27-40-06-29 |            |             |

### Approvals

|      |         |
|------|---------|
| ROHS | Conform |
|------|---------|

### Downloads

|                  |                       |
|------------------|-----------------------|
| Engineering Data | <a href="#">EPLAN</a> |
|------------------|-----------------------|

**THM**  
**THM ET S7 1500-13 TU**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 16  
D-32758 Detmold  
Germany  
Fon: +49 5231 14-0  
Fax: +49 5231 14-292083  
[www.weidmueller.com](http://www.weidmueller.com)

**Drawings**

