

ESG
ESG 9/17 MM GE VPE1000**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16

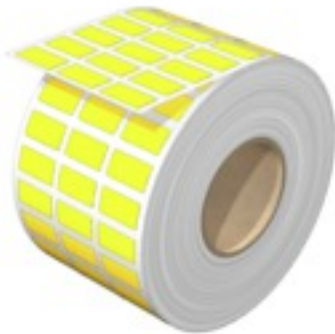
D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

**Guaranteed long service life: ESG**

The multi-colour and multi-format labels have a strong adhesive layer to ensure the best possible adhesion to the underlying surface. Double laminated polyester makes the basic material very thin and yet extremely tear-resistant.

Your benefits with MultiMark

- Double laminated polyester
- Can be used with equipment from many manufacturers
- Device markers with a familiar design

General ordering data

Type	ESG 9/17 MM GE VPE1000
Order No.	2496820000
Version	ESG, Device markers, 9 x 17 mm, yellow
GTIN (EAN)	4050118508321
Qty.	1,000 pc(s).
compatible printer	2430920000 2448870000

ESG

ESG 9/17 MM GE VPE1000

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
www.weidmueller.com

Technical data

Dimensions and weights

Width	17 mm	Width (inches)	0.669 inch
Height	9 mm	Height (inches)	0.354 inch
Depth	0.1 mm	Depth (inches)	0.004 inch
Net weight	0.043 g		

General data

Adhesive	Acrylate adhesive	Approval acc. to UL 969	Yes
Colour	yellow	Halogen	No
Material	Polyester	Number per roll	1,000
Operating temperature range	-40... 120 °C	UL 94 flammability rating	V-0
Version	Self-adhesive, halogen-free	Width	17 mm

Classifications

ETIM 6.0	EC001288	eClass 6.2	27-14-91-29
eClass 9.0	27-40-06-29	eClass 9.1	27-40-06-29

Approvals

ROHS	Conform
------	---------

Downloads

Engineering Data	EPLAN
------------------	-----------------------

ESG **ESG 9/17 MM GE VPE1000**

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

Drawings

