


ESG ESG 9/26 SCM-I MC NE WS

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

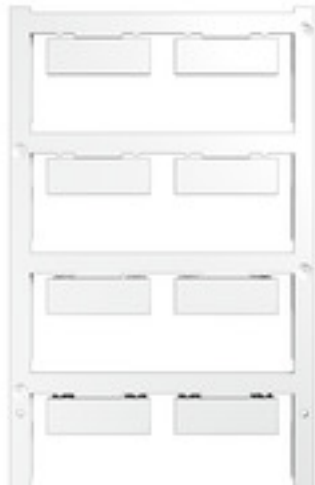

The Weidmüller device markers enable users to conform to obligatory equipment labelling regulations. Users can label the device markers themselves by means of suitable software and system-compatible printer systems.

ESG is the tried-and-tested marker in MultiCard format. The result is high-quality device marking with a high-contrast appearance.

ESG 9/26 SCM-I MC... for marking RIDERSERIES RCM relay sockets:

- Attachable MultiCard markers
- Attachable on all 4 levels of the relay socket
- PrintJet printable

General ordering data

Type	ESG 9/26 SCM-I MC NE WS
Order No.	2558330000
Version	ESG, Device markers x 26 mm, Colour: white
GTIN (EAN)	4050118569049
Qty.	80 pc(s).
compatible printer	1324380000

Data sheet

ESG ESG 9/26 SCM-I MC NE WS

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

Technical data

Dimensions and weights

Width	26 mm	Width (inches)	1.024 inch
Height	9 mm	Height (inches)	0.354 inch
Net weight	0.963 g		

Temperatures

Operating temperature range	-40...100 °C	Operating temperature range, max.	100 °C
Operating temperature range, min.	-40 °C		

General data

Colour	white	UL 94 flammability rating	V-2
--------	-------	---------------------------	-----

Classifications

ETIM 6.0	EC001288	eClass 6.2	27-14-91-29
eClass 9.0	27-40-06-29	eClass 9.1	27-40-06-29

Approvals

ROHS	Conform
------	---------

Downloads

Engineering Data	STEP
------------------	----------------------

Data sheet

ESG
ESG 9/26 SCM-I MC NE WS

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

Drawings

