

**THM
THM ET S7 1500 TU****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16


D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

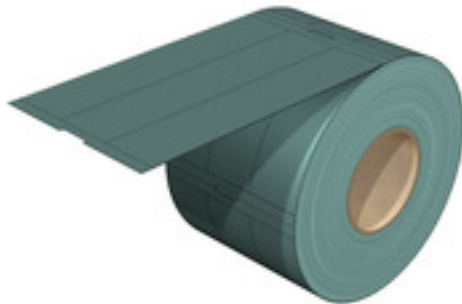

THM ET S7 non-adhesive, roll-packaged labels are used to label the SIMATIC ET 200S, S7-300 and S7-400 modules from Siemens.

- The M-Print® PRO software can be used to individually print the THM ET S7 labels with a THM printer.
- Labels can be easily separated
- The THM Plus S printer ensures highly-resistant printing

General ordering data

Type	THM ET S7 1500 TU
Order No.	1991680000
Version	THM, Device markers, 108.8 x 22.9 mm, Siemens, Turquoise
GTIN (EAN)	4050118376333
Qty.	500 pc(s).
compatible printer	2430920000 2448870000

THM
THM ET S7 1500 TU
Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

Technical data
Dimensions and weights

Width	22.9 mm	Width (inches)	0.902 inch
Height	108.8 mm	Height (inches)	4.283 inch
Depth	0.08 mm	Depth (inches)	0.003 inch
Net weight	0.678 g		

General data

Application/manufacture	Siemens	Approval acc. to UL 969	No
Colour	Turquoise	Halogen	No
Material	Polypropylene	Number per roll	500
Operating temperature range	-50...100 °C	Printing method	Thermotransfer
UL 94 flammability rating	HB	Version	halogen-free
Width	22.9 mm		

Classifications

ETIM 5.0	EC001288	ETIM 6.0	EC001288
eClass 6.2	27-14-91-29	eClass 9.0	27-40-06-29
eClass 9.1	27-40-06-29		

Approvals

ROHS	Conform
------	---------

Downloads

Engineering Data	EPLAN, WSCAD
------------------	------------------------------