

TL2 10DA LSA (907 996)

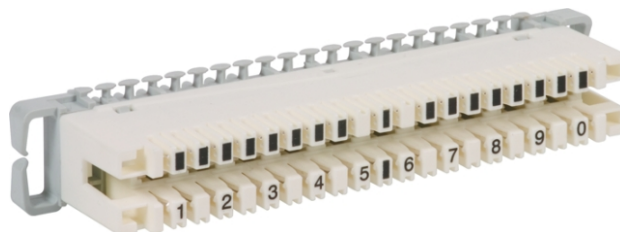


Figure without obligation

Series 2 for LSA technology for connecting 10 pairs each on the cable and routing side. Protection is provided between the disconnection contacts as soon as DRL components are plugged in. DPL 10 G3 arresters can also be plugged into the disconnection block.

Type	TL2 10DA LSA
Part No.	907 996
Enclosure material	PBT
Test standards	DIN 47608-1, -2
Approvals	compliance with DTAG TS 0272/96
Diameter of solid conductors	0.40-0.80 mm
Conductor diameter with insulation	0.70-1.50 mm
Contacting frequency for conductor diameters ≤ 0.65 mm	> 50 x
Contacting frequency for conductor diameters of 0.8 mm	≤ 50 x
Contact material	special brass
Contact surface	silver
Flame protection	UL 94 V-0
Insulation resistance	5x 10.000 Mohms
Volume resistance of IPC terminal	< 10 mohms
Electric strength	2 kV / 50 Hz
Weight	60 g
Customs tariff number (Comb. Nomenclature EU)	85369010
GTIN	4013364033535
PU	1 pc(s)

We reserve the right to introduce changes in performance, configuration and technology, dimensions, weights and materials in the course of technical progress. The figures are shown without obligation.