




IGA 6 IP54 (902 485)

- Lightning-impulse-current-tested insulating enclosure for arresters



Figure without obligation

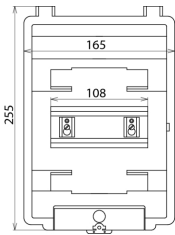

Dimension drawing IGA 6 IP54

Lightning-current-tested insulating enclosure with a max. capacity of six modules for arresters without venting means; with knockouts for entering the cables and plug-in glands; ideally suited for series connection.

Type	IGA 6 IP54
Part No.	902 485
Degree of protection	IP 54
Type	lightning-current-tested
Type of cover	transparent
Colour of enclosure	grey
Number of knockouts	4x M20; 2x M25/32; 1x M 32/40 (top and bottom)
Number of cable entries	2 plug-in glands for cables Ø8-23 mm (M32 knockout)
Capacity	6 modules, DIN 43880
Dimensions (W x H x D)	165 x 255 x 115 mm
Cover	sealable
Weight	612 g
Customs tariff number (Comb. Nomenclature EU)	85381000
GTIN	4013364045767
PU	1 pc(s)

We reserve the right to introduce changes in performance, configuration and technology, dimensions, weights and materials in the course of technical progress. The figures are shown without obligation.