

MVK 8.10 SKM10X35 V4A (390 079)

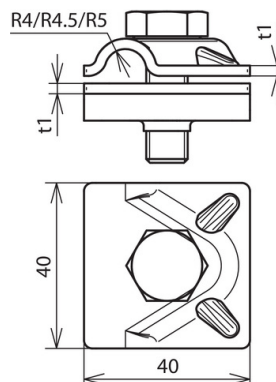
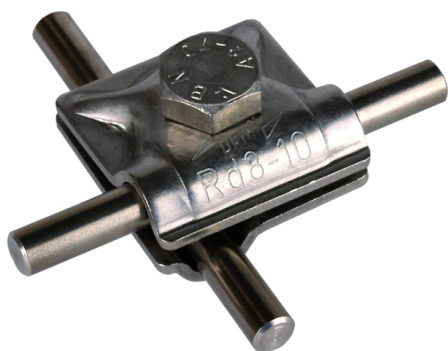


Figure without obligation

Clamp also suits for underground application.

Type	MVK 8.10 SKM10X35 V4A
Part No.	390 079 ✓
Material of clamp	StSt (V4A)
Clamping range Rd	8-10 mm
Material thickness (t1 / t2)	2.5 mm
Screw	● M10 x 35 mm
Material of screw / nut	StSt (V4A)
Material No.	1.4571 / 1.4404 / 1.4401
ASTM / AISI:	316Ti / 316L / 316
Standard	EN 62561-1
Short-circuit current (50 Hz) (1 s; ≤ 300 °C)	4.7 kA
Weight	96 g
Customs tariff number (Comb. Nomenclature EU)	85389099
GTIN	4013364128996
PU	50 pc(s)

Note: Part No. 390 079 made of StSt (V4A) also suitable for underground application.

We reserve the right to introduce changes in performance, configuration and technology, dimensions, weights and materials in the course of technical progress. The figures are shown without obligation.