

## BRS 27.60 AQ4 25 V2A (540 910)

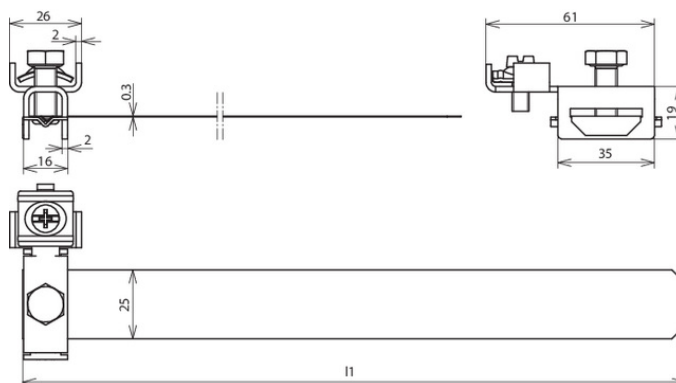


Figure without obligation

Type	BRS 27.60 AQ4 25 V2A
Part No.	540 910
Material	StSt
Clamping range pipe Ø	27-60 mm ( <sup>3</sup> / <sub>4</sub> -2")
Screw	☛ M8 x 20 / ☛ M6 x 16 mm
Material of screw	StSt
Dimension of strap (l1 x w x d)	240 x 25 x 0,3 mm
Connection (solid / stranded)	4-25 mm <sup>2</sup>
Two-wire connection	yes
Feed-through wiring	yes
Standard	EN 62561-1
Application notes	suitable for outdoor use
Weight	71 g
Customs tariff number (Comb. Nomenclature EU)	85389099
GTIN	4013364025684
PU	10 pc(s)

We reserve the right to introduce changes in performance, configuration and technology, dimensions, weights and materials in the course of technical progress. The figures are shown without obligation.