




## BRS 16.168 AK1X10 2X6.8 V2A (540 100)



Figure without obligation

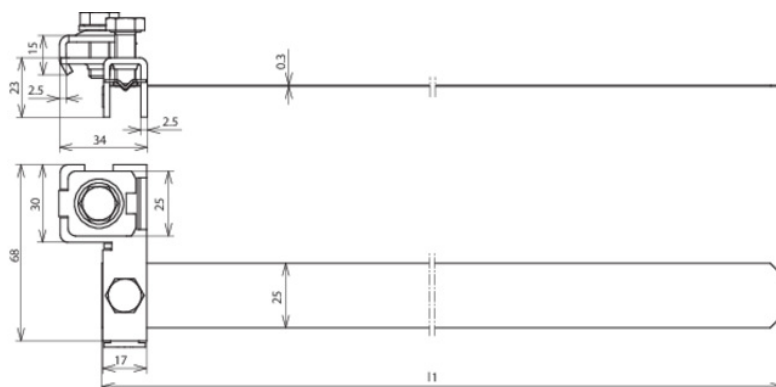

Type	BRS 16.168 AK1X10 2X6.8 V2A
Part No.	540 100
Material	StSt
Clamping range pipe Ø	16-168 mm ( <sup>3</sup> / <sub>4</sub> -6")
Screw	☒ M8 x 20 mm
Material of screw	StSt
Dimension of strap (l1 x w x d)	570 x 25 x 0.3 mm
Connection Rd	1-2 conductors Rd Ø6-8 mm / 1x Ø10 mm
Connection (solid / stranded)	4-50 mm <sup>2</sup>
Standard	EN 62561-1
Weight	133 g
Customs tariff number (Comb. Nomenclature EU)	85389099
Stock No.	5975-12-120-7744
GTIN	4013364094109
PU	10 pc(s)

We reserve the right to introduce changes in performance, configuration and technology, dimensions, weights and materials in the course of technical progress. The figures are shown without obligation.