

MVK 8.10 SKM10X30 STTZN (390 050)


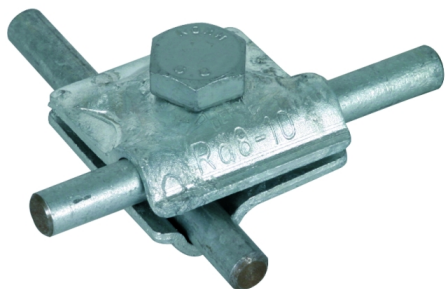


Figure without obligation

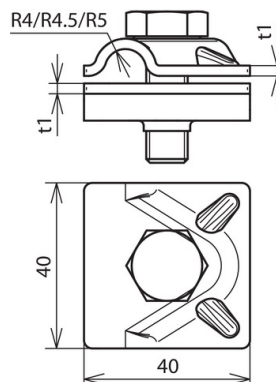

Type	MVK 8.10 SKM10X30 STTZN
Part No.	390 050 ✓
Material of clamp	St/tZn
Clamping range Rd	8-10 mm
Material thickness (t1 / t2)	2.5 mm
Screw	● M10 x 30 mm
Material of screw / nut	St/tZn
Standard	EN 62561-1
Short-circuit current (50 Hz) (1 s; ≤ 300 °C)	5.5 kA
Weight	99 g
Customs tariff number (Comb. Nomenclature EU)	85389099
GTIN	4013364095991
PU	50 pc(s)

Note: Part No. 390 079 made of StSt (V4A) also suitable for underground application.

We reserve the right to introduce changes in performance, configuration and technology, dimensions, weights and materials in the course of technical progress. The figures are shown without obligation.