




RRS V 60.150 B10.5 STTZN (423 020)



Figure without obligation

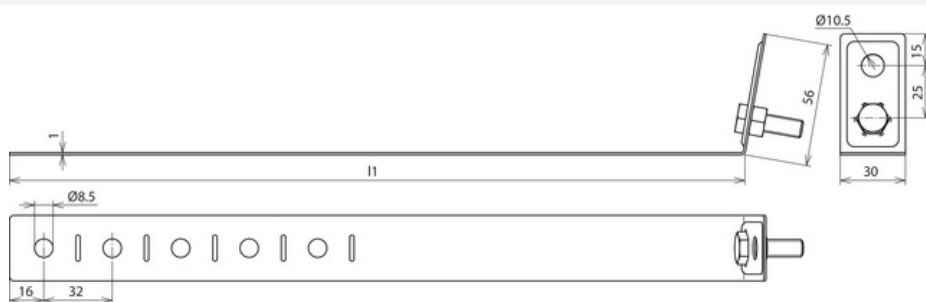

| Type | RRS V 60.150 B10.5 STTZN |
|---|--------------------------|
| Part No. | 423 020 |
| Material | St/tZn |
| Clamping range pipe Ø (d1) | 60-150 mm |
| Length (l1) | 494 mm |
| Bore Ø | 10.5 mm |
| Screw | ☛ M8 x 25 mm |
| Material of screw / nut | StSt |
| Standard | EN 62561-1 |
| Weight | 138 g |
| Customs tariff number (Comb. Nomenclature EU) | 85389099 |
| GTIN | 4013364054288 |
| PU | 50 pc(s) |

We reserve the right to introduce changes in performance, configuration and technology, dimensions, weights and materials in the course of technical progress. The figures are shown without obligation.