



KS FL30 V4A (318 233)

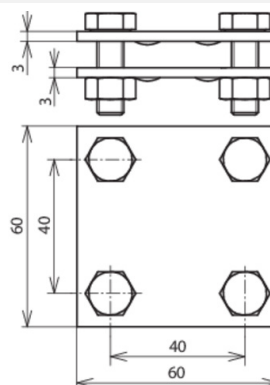
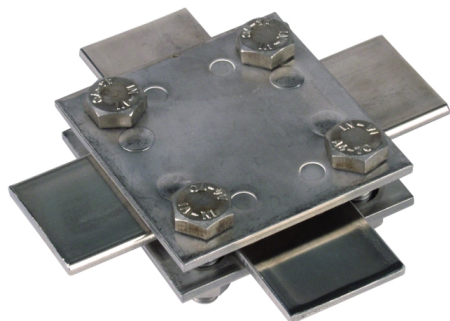


Figure without obligation

Type	KS FL30 V4A
Part No.	318 233
Material of clamp	StSt (V4A)
Clamping range FI / FI	30 / 30 mm
Screw	⚙ M8 x 25 mm
Material of screw / nut	StSt (V4A)
Material No.	1.4571 / 1.4404 / 1.4401
ASTM / AISI:	316Ti / 316L / 316
Dimension	60 x 60 x 3 mm
Standard	EN 62561-1
Short-circuit current (50 Hz) (1 s; ≤ 300 °C)	7.0 kA
Weight	225 g
Customs tariff number (Comb. Nomenclature EU)	85389099
GTIN	4013364096646
PU	25 pc(s)

We reserve the right to introduce changes in performance, configuration and technology, dimensions, weights and materials in the course of technical progress. The figures are shown without obligation.