


DIDH 16 530 RS40.60 V2A (106 225)

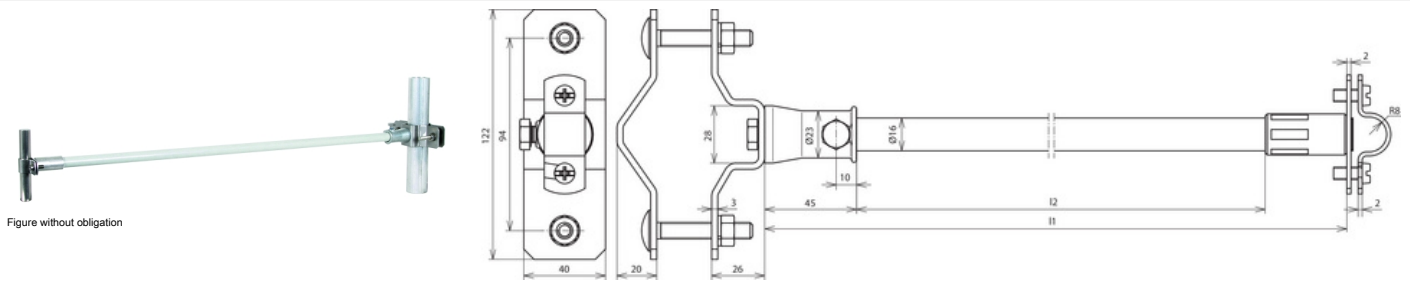

Type	DIDH 16 530 RS40.60 V2A
Part No.	106 225
Conductor holder support Rd	16 mm
Material of conductor holder	StSt
Length (l1)	530 mm
Insulating clearance (l2)	445 mm
Clamping range of pipe	40-60 mm (1 1/4-2")
Diameter Ø of spacer	16 mm
Colour of spacer	light grey (RAL 7035) •
Conductor leading	fixed
Rod / Conductor holder	two-screw cleat
Material of spacer	GRP
Material factor km	0.7
Permanent temperature range	-50 °C ... +100 °C
Material of fixing bush	ZDC
Material of fixing element	StSt
Type	UV stabilised and weather resistant
Max. gust wind speed mounting possibility 2	130 km/h
Weight	684 g
Customs tariff number (Comb. Nomenclature EU)	85389099
GTIN	4013364100299
PU	1 pc(s)

We reserve the right to introduce changes in performance, configuration and technology, dimensions, weights and materials in the course of technical progress. The figures are shown without obligation.

Design with other lengths of spacer bar upon request.