




## AK TE 20 7.10 FL40 V4A (610 020)



Figure without obligation

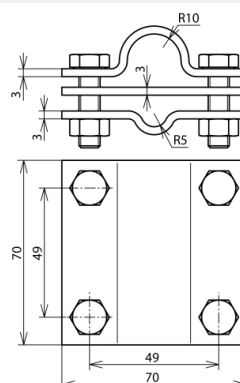

Type Part No.	AK TE 20 7.10 FL40 V4A 610 020
Material	StSt (V4A)
Material No.	1.4571 / 1.4404 / 1.4401
ASTM / AISI:	316Ti / 316L / 316
For earth rods Ø	20 mm
Clamping range Rd / FI	7-10 / -40 mm
Clamping range (stranded / cable)	35-70 mm <sup>2</sup>
Screw	● M8 x 30 mm
Material of screw / nut	StSt (V4A)
Short-circuit current (50 Hz) (1 s; ≤ 300 °C)	8 kA
Standard	EN 62561-1
Weight	436 g
Customs tariff number (Comb. Nomenclature EU)	85389099
GTIN	4013364054110
PU	25 pc(s)

We reserve the right to introduce changes in performance, configuration and technology, dimensions, weights and materials in the course of technical progress. The figures are shown without obligation.