



## AS S TE 25 7.10 FL40 V4A (649 015)

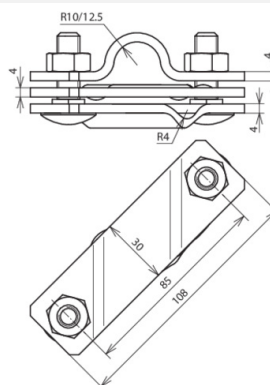


Figure without obligation

Type	AS S TE 25 7.10 FL40 V4A
Part No.	649 015
Material	StSt (V4A)
Clamping range Rd / Fl	7-10 / -40 mm
Clamping range (stranded / cable)	35-95 mm <sup>2</sup>
Type for earth rods	Ø25 mm
Screw	☛ M10 x 35 mm
Material of screw / nut	StSt (V4A)
Material No.	1.4571 / 1.4404 / 1.4401
Short-circuit current (50 Hz) (1 s; ≤ 300 °C)	8 kA
Weight	300 g
Customs tariff number (Comb. Nomenclature EU)	85389099
GTIN	4013364119376
PU	20 pc(s)

We reserve the right to introduce changes in performance, configuration and technology, dimensions, weights and materials in the course of technical progress. The figures are shown without obligation.