


DC BK 8 RD10 STBLANK (308 131)



Figure without obligation

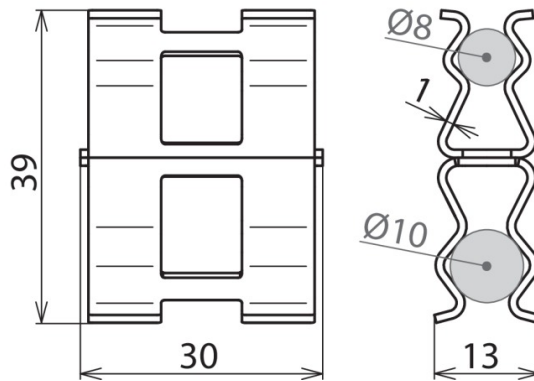

- Compact, light and resource-saving
- Quick and toolless
- Efficient and time-saving

Type	DC BK 8 RD10 STBLANK
Part No.	308 131
Material	St/bare
Clamping range Rd* / Rd	8-9 / 10 mm
Material thickness (t1)	1 mm
Short-circuit current (50 Hz) (1 s; ≤ 300 °C)	2.7 kA
Standard	EN 62561-1
Weight	18 g
Customs tariff number (Comb. Nomenclature EU)	85389099
GTIN	4013364288881
PU	50 pc(s)

* Nominal diameter d_s of the reinforcement

We reserve the right to introduce changes in performance, configuration and technology, dimensions, weights and materials in the course of technical progress. The figures are shown without obligation.