

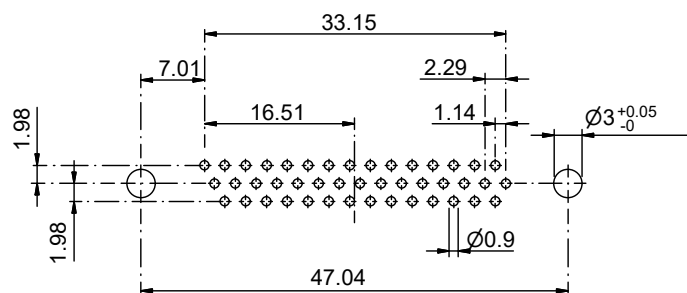
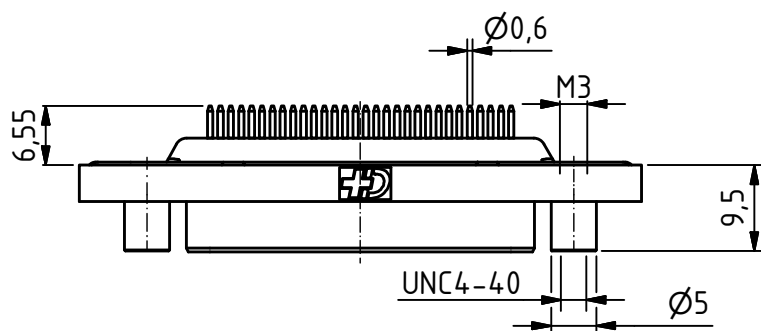
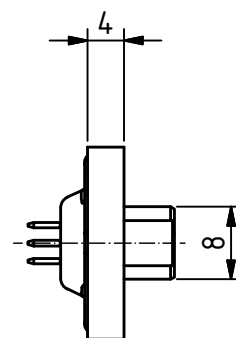


RoHS compliant

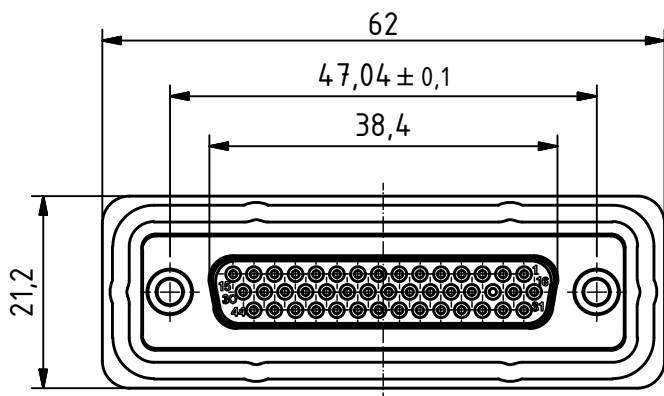

PCB Layout
tolerances +/-0.1

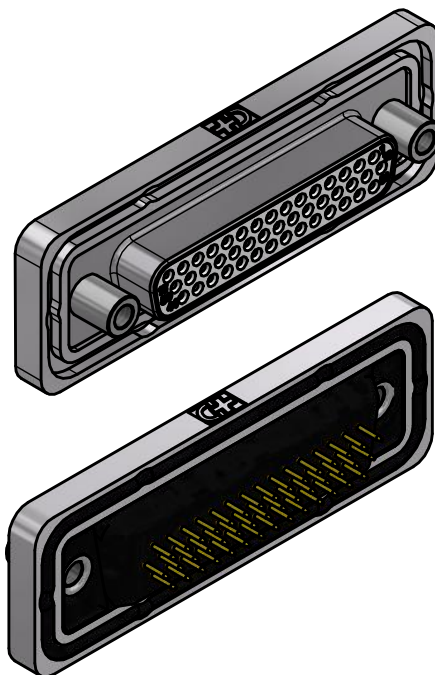

Waterproof IP68

Frame with O-ring sealing for front panel mounting

MATERIALS

- Insulator: Thermoplastic UL 94-V-0 white
- Frame: Zinc diecasting nickel plated
- Contact: Machined / Copper alloy
- Contact finish: Quality class 2
- Shell: steel tin plated

CHARAKTERISTICS

- Working voltage: 60V
- Current rating: 5A
- Contact resistance: max. 10mΩ - DIN41652
- Insulation resistance: >5GΩ
- Temperature range: -55° to +125°C

General tolerances (Deltron standard)				
size in mm	tolerances			
	> 0.5 up to 3	> 3 up to 6	> 6 up to 30	> 30 up to 120
	±0.1	±0.2	±0.2	±0.3

modification	Rev.	Rev.	Rev.	DE017222		
	Rev.	Rev.	Rev.	part no.		
HD-DWM44SY/2M95UN			1.5:1	drawn	01.03.2016	mw
			scale	checked		
				approved		
DELTRON CONNECT 2 CUSTOMIZE			Industrie NeuhoF 8c CH-3422 Kirchberg www.d-sub.swiss			
			K062452 drawing no.			