



RoHS compliant

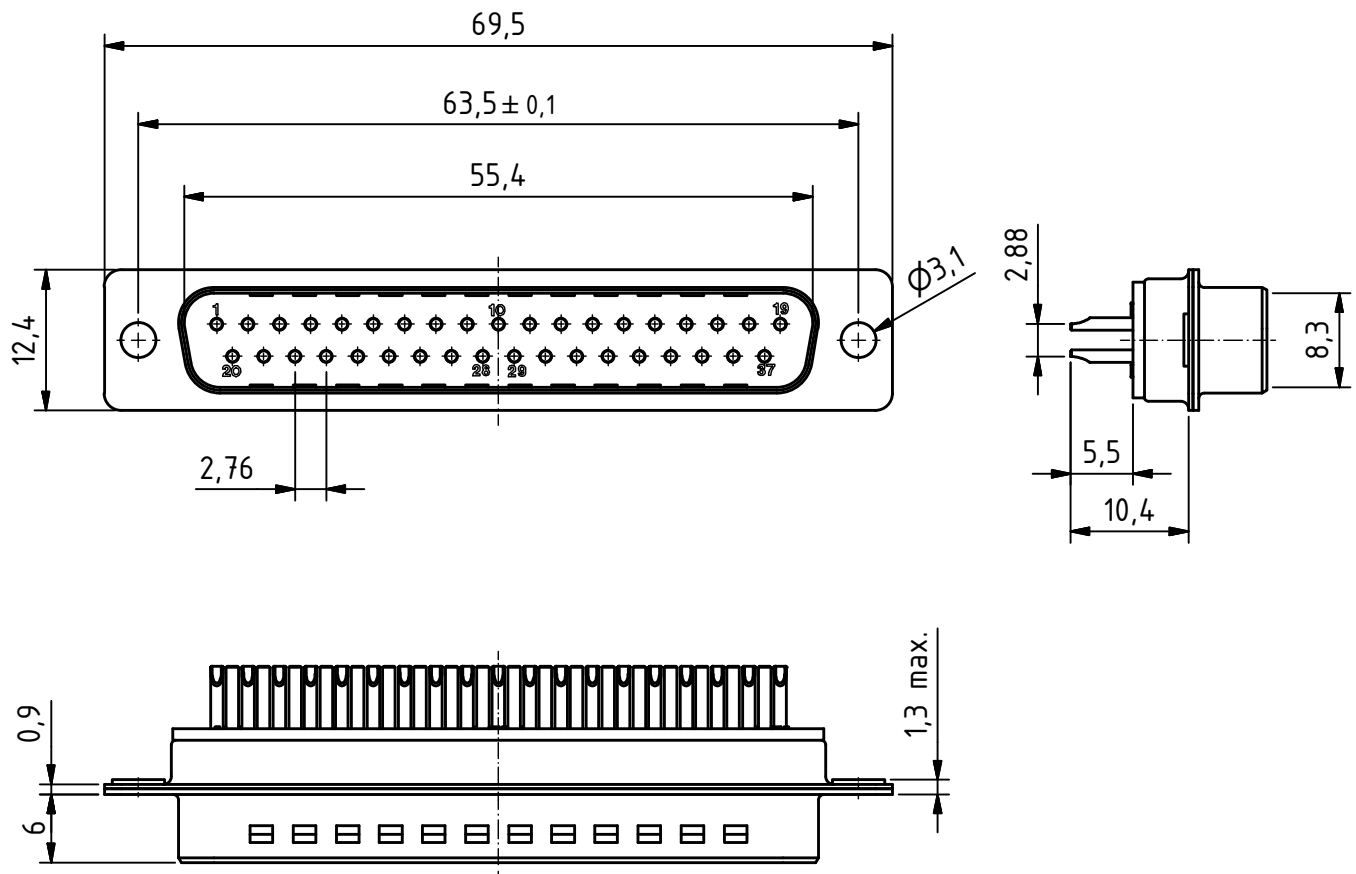

suitable for cable AWG 22

Capacitor value 1'000 pF

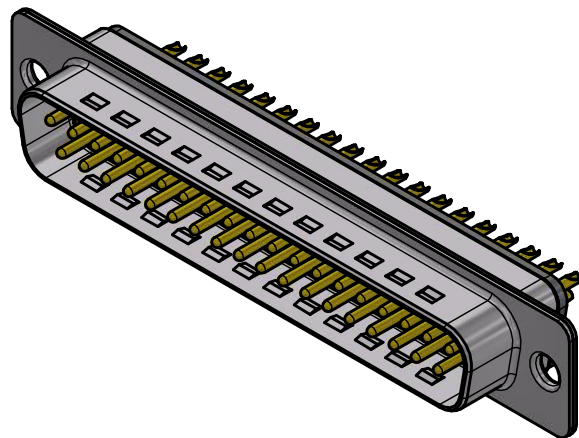

MATERIALS

- Insulator: Thermoplastic UL 94-V-0 black
- Contact: Machined / Copper alloy
- Contact finish: Quality class 2
- Shell: steel tin plated

CHARAKTERISTICS

- Working voltage: 100V
- Current rating: 7.5A
- Contact resistance: max. 10mΩ - DIN41652
- Insulation resistance: >1GΩ
- Temperature range: -55° to +125°C

General tolerances (Deltron standard)				
size in mm				
> 0,5 up to 3	> 3 up to 6	> 6 up to 30	> 30 up to 120	
tolerances				
±0,1	±0,2	±0,2	±0,3	

modification	Rev.	Rev.	Rev.	DE002746		
	Rev.	Rev.	Rev.	part no.		
D37PZ/2FP102			1.5:1	drawn	06.11.2007	mr
			scale	checked		
				approved		
DELTRON CONNECT 2 CUSTOMIZE			Industrie Neuhof 8c CH-3422 Kirchberg www.d-sub.swiss	K052008		
				drawing no.		