
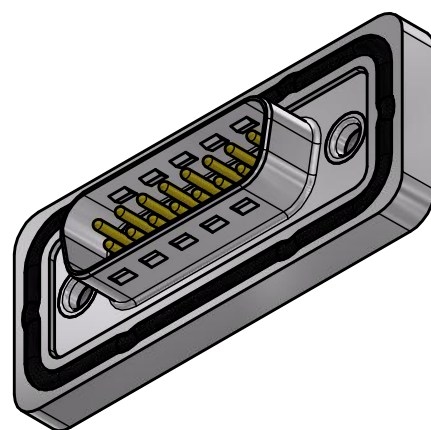
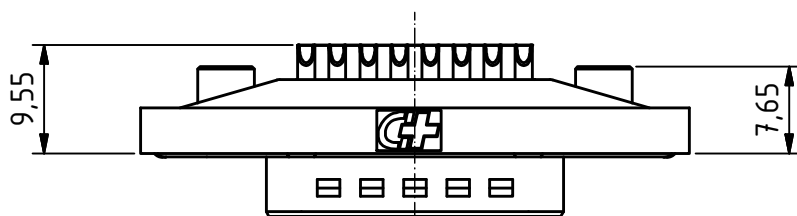
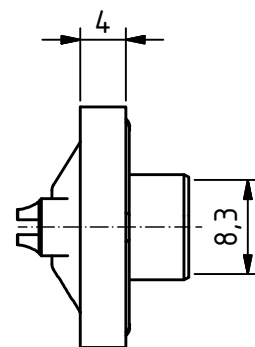


RoHS compliant

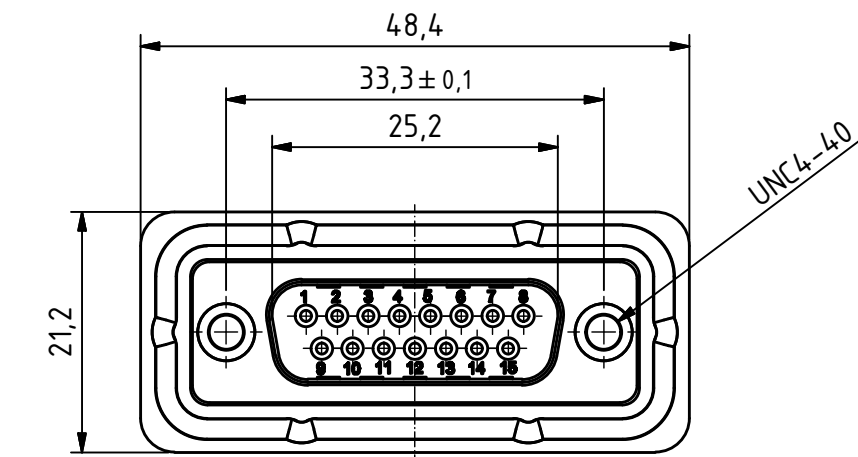

suitable for cable AWG 18

Waterproof IP68

Frame with O-ring sealing for back panel mounting

MATERIALS

- Insulator: Thermoplastic UL 94-V-0 white
- Frame: Zinc diecasting nickel plated
- Contact: Machined / Copper alloy
- Contact finish: Quality class 2
- Shell: steel tin plated

CHARAKTERISTICS

- Working voltage: 125V
- Current rating: 7.5A
- Contact resistance: max. 10mΩ - DIN41652
- Insulation resistance: >5GΩ
- Temperature range: -55° to +125°C

General tolerances (Delttron standard)				
size in mm				
> 0.5	> 3	> 6	> 30	
up to 3	up to 6	up to 30	up to 120	
tolerances				
±0.1	±0.2	±0.2	±0.3	

modification	Rev.	Rev.	Rev.	DE017067 part no.		
	Rev.	Rev.	Rev.			
DTSWM15PZ/2M85UN			1.5:1	drawn	18.11.2015	mw
			scale	checked		
				approved		
DELTRON CONNECT 2 CUSTOMIZE			Industrie Neuhof 8c CH-3422 Kirchberg www.d-sub.swiss			
			K062342 drawing no.			