

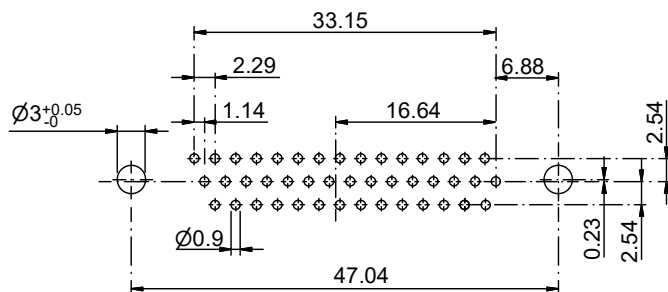
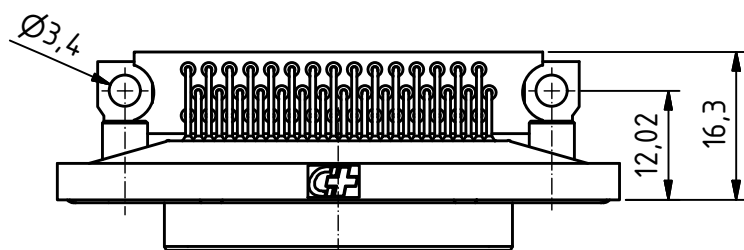
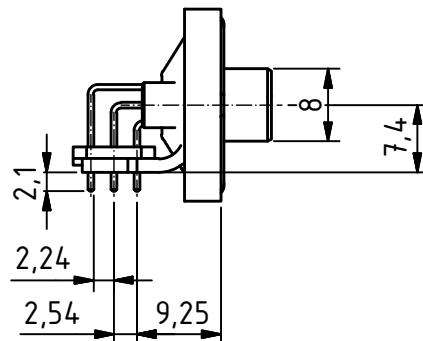


RoHS compliant

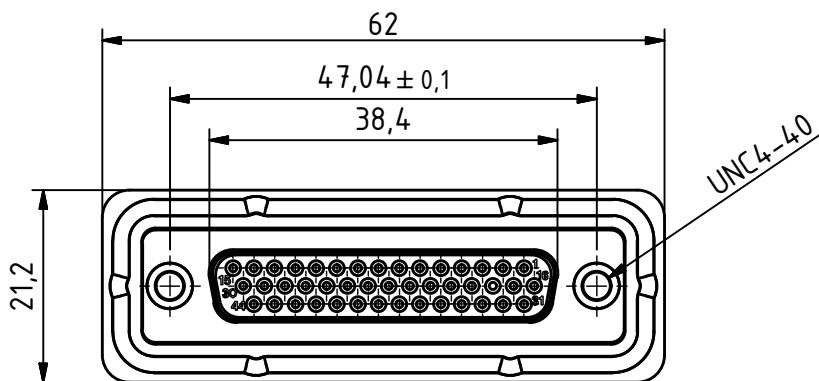

PCB Layout
tolerances +/-0.1

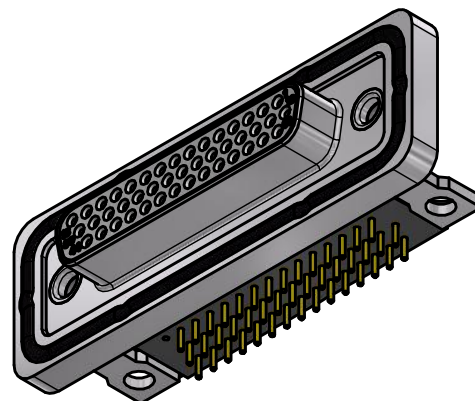

Waterproof IP68

Frame with O-ring sealing for back panel mounting

MATERIALS

- Insulator: Thermoplastic UL 94-V-0 white
- Frame: Zinc diecasting nickel plated
- Contact: Machined / Copper alloy
- Contact finish: Quality class 2
- Shell: steel tin plated

CHARAKTERISTICS

- Working voltage: 60V
- Current rating: 5A
- Contact resistance: max. 10mΩ - DIN41652
- Insulation resistance: >5GΩ
- Temperature range: -55° to +125°C

General tolerances (Deltron standard)				
size in mm	> 0.5	> 3	> 6	> 30
	up to 3	up to 6	up to 30	up to 120
tolerances				
	±0.1	±0.2	±0.2	±0.3

modification	Rev.	Rev.	Rev.	DE017200		
	Rev.	Rev.	Rev.	part no.		
HD-DWM44SYC/2M46UN			1.2:1 scale	drawn	25.02.2016	mw
				checked		
				approved		
DELTRON CONNECT 2 CUSTOMIZE SWISS			Industrie Neuhof 8c CH-3422 Kirchberg www.d-sub.swiss			K062453 drawing no.