


## 6/3 FAN PACK User's Manual

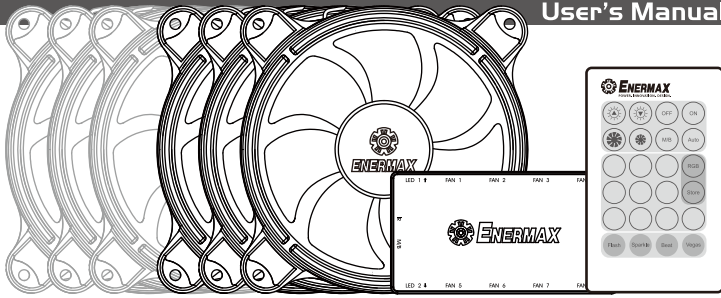


Model Number	UCTBRGB12-BP3	UCTBRGB12-BP6
Dimension (mm)	120(W) x 120(H) x 25(D)	
Speed (RPM)	500-1500 (±10%)	
Air Flow (CFM)	47.53 (max)	
Air Flow (m³/h)	80.75 (max)	
Static Pressure (mm-H <sub>2</sub> O)	1.66 (max)	
Maximum Noise (dBA)	22	
Rated Current- Fan (A)	0.15	
Rated Current- RGB LED (A)	0.3	
Rated Voltage (V)	12	
MTBF (hours)	≥160,000 @ 25°C	
Connector	6-PIN	
Warranty	1 year	
Package contents	T.B.RGB fan x 3 Screw x 12 Control box x 1 Remote control x 1	T.B.RGB fan x 6 Screw x 24 Control box x 1 Remote control x 1

© 2017 ENERMAX TECHNOLOGY CORPORATION. All right reserved.  
Specifications are subject to change without prior notice. Some trademark may be claimed as the property of others.


※ Product specifications are subject to change without prior notice.  
※ For detailed information, please visit our website at [www.enermax.com](http://www.enermax.com).

## Chapter 2 - Part List

- A** T.B. RGB fan (6 fan pack x 6, 3 fan pack x 3)    **B** Control box x 1    **C** Infrared sensor x 1    **D** Power cable x 1

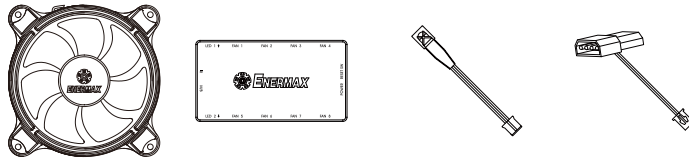


- E** M/B sync cable x 1    **F** Screw (6 fan pack x 24, 3 fan pack x 12)    **G** Magnetic adhesive x 2 / Velcro x 1    **H** Remote control x 1

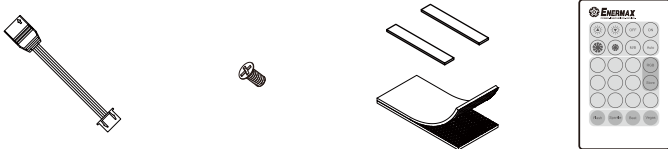

\*Notice: Actual specifications / product parts may vary according to different regions or countries.

## Chapter 3 - Remote Control Overview

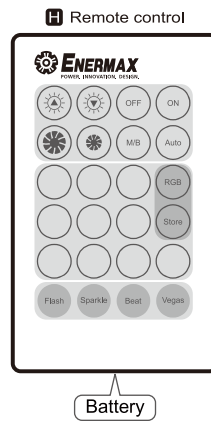

Function	Icon	Description
Brightness / Lighting Speed	☀️	Brightness / Lighting Speed
OFF/ON	⏻ / ⏪	OFF/ON
Fan Speed Fast/Slow	🌀 / 🌀	Fan Speed Fast/Slow
Motherboard Sync switch	M/B	Motherboard Sync switch
Preset 10 colors with flash effect	Auto	Preset 10 colors with flash effect
Colors	RGB	RGB colors automatically rotate
	Stop	Fix your preferred color in RGB mode
	LED	LED colors
Light Effects	Flash	Flash
	Sparkle	Sparkle
	Beat	Beat
	Vegas	3 modes repeated

## Chapter 4 - Control Box Installation Guide

