


Han TC650 female contact 120mm²

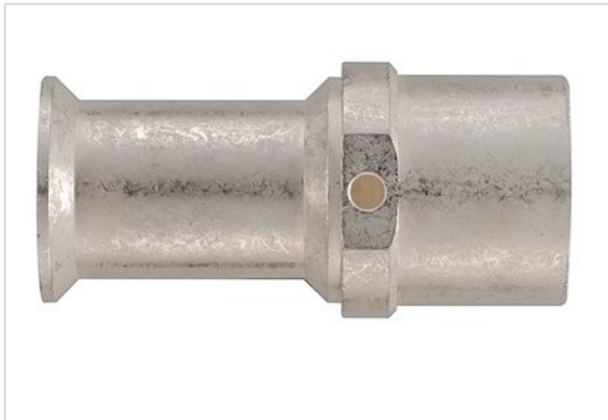

Part number	09 11 000 6263
Specification	Han TC650 female contact 120mm ²
HARTING eCatalogue	https://b2b.harting.com/09110006263

Identification

Category	Contacts
Series	TC 650
Type of contact	Crimp contact

Version

Gender	Female
--------	--------

Technical characteristics

Conductor cross-section	120 mm ²
Operating current	≤650 A
Contact resistance	≤0.3 mΩ
Limiting temperature	-40 ... +125 °C
Stripping length	42 mm
Mating cycles	≥500

Material properties

Material (contacts)	Copper alloy
Surface (contacts)	Silver plated
RoHS	compliant with exemption
RoHS exemptions	6c: Copper alloy containing up to 4 % lead by weight
ELV status	compliant with exemption
China RoHS	50
REACH Annex XVII substances	No
REACH ANNEX XIV substances	No
REACH SVHC substances	Yes
REACH SVHC substances	Lead

Specifications and approvals

Specifications	EN 60664-1
----------------	------------



Pushing Performance

Specifications and approvals

IEC 61984

Commercial data

Packaging size	1
Net weight	124.7 g
Country of origin	Germany
Customs tariff number	85359000