


Han D 25 Pos. F Insert Wire Wrap

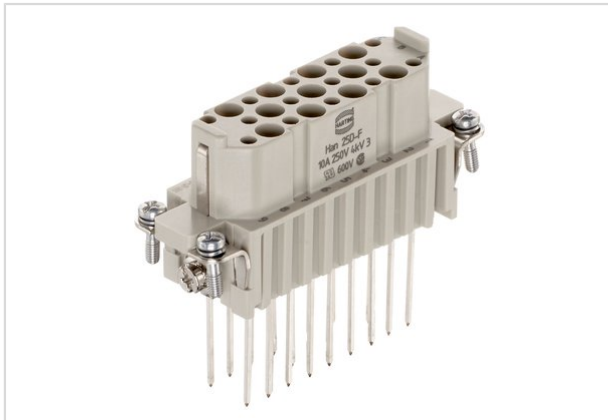

Part number	09 21 025 2701
Specification	Han D 25 Pos. F Insert Wire Wrap
HARTING eCatalogue	https://b2b.harting.com/09210252701

Identification

Category	Inserts
Series	Han D®

Version

Termination method	Wrap termination
Gender	Female
Size	16 A
Number of contacts	25
PE contact	Yes
Termination length	22 mm

Technical characteristics

Dimensions wire wrap post	1 x 1 mm
Electrical data acc. to IEC 61984	10 A 250 V 4 kV 3
Rated current	10 A
Rated voltage	250 V
Rated impulse voltage	4 kV
Pollution degree	3
Rated voltage acc. to UL	600 V
Rated voltage acc. to CSA	600 V
Insulation resistance	$\geq 10^{10} \Omega$
Contact resistance	$\leq 3 \text{ m}\Omega$
Limiting temperature	-40 ... +125 °C
Mating cycles	≥ 500

Material properties

Material (insert)	Polycarbonate
Colour (insert)	RAL 7032 (pebble grey)



Pushing Performance

Material properties

Material (contacts)	Copper alloy
Surface (contacts)	Silver plated
Material flammability class acc. to UL 94	V-0
RoHS	compliant with exemption
RoHS exemptions	6c: Copper alloy containing up to 4 % lead by weight
ELV status	compliant with exemption
China RoHS	50
REACH Annex XVII substances	No
REACH ANNEX XIV substances	No
REACH SVHC substances	Yes
REACH SVHC substances	Lead

Specifications and approvals

Specifications	EN 60664-1
	IEC 61984
	EN 175301-801
Approvals	DNV GL
UL / CSA	UL 1977 ECBT2.E235076
	CSA-C22.2 No. 182.3 ECBT8.E235076

Commercial data

Packaging size	9
Net weight	59.8 g
Country of origin	Romania
Customs tariff number	85366990