


Han 200A PE axial module female 25-40mm²

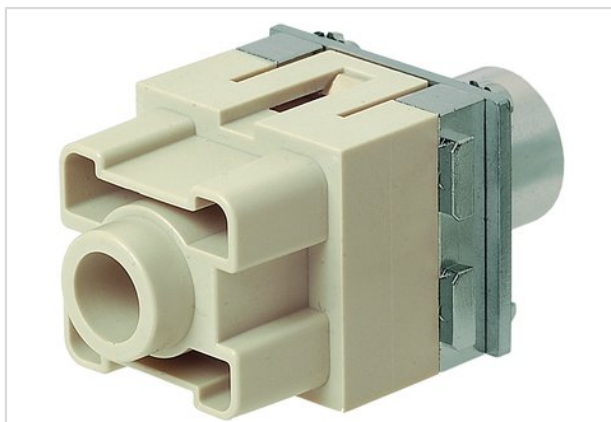

Part number	09 14 001 2768
Specification	Han 200A PE axial module female 25-40mm²
HARTING eCatalogue	https://b2b.harting.com/09140012768

Identification

Category	Modules
Series	Han-Modular®
Type of module	Han® 200 A PE module

Version

Termination method	Axial screw termination
Gender	Female
Number of contacts	1

Technical characteristics

Conductor cross-section	25 ... 40 mm²
Contact resistance	≤0.2 mΩ
Limiting temperature	-40 ... +125 °C
Stripping length	16 mm
Tightening torque	8 Nm
Mating cycles	≥500

Material properties

Material (insert)	Polycarbonate
Colour (insert)	RAL 7032 (pebble grey)
Material (contacts)	Copper alloy
Surface (contacts)	Silver plated
Material flammability class acc. to UL 94	V-0
RoHS	compliant with exemption
RoHS exemptions	6a: Lead as an alloying element in steel for machining purposes and in galvanised steel containing up to 0,35 % lead by weight 6c: Copper alloy containing up to 4 % lead by weight
ELV status	compliant with exemption
China RoHS	50



Pushing Performance

Material properties

REACH Annex XVII substances	No
-----------------------------	----

REACH ANNEX XIV substances	No
----------------------------	----

REACH SVHC substances	Yes
-----------------------	-----

REACH SVHC substances	Lead
-----------------------	------

Specifications and approvals

Specifications	EN 60664-1
	IEC 61984

Approvals	DNV GL
-----------	--------

UL / CSA	UL 1977 ECBT2.E235076
----------	-----------------------

Commercial data

Packaging size	1
----------------	---

Net weight	96 g
------------	------

Country of origin	Germany
-------------------	---------

Customs tariff number	85389099
-----------------------	----------