


## Han FireWire modul female gender changer

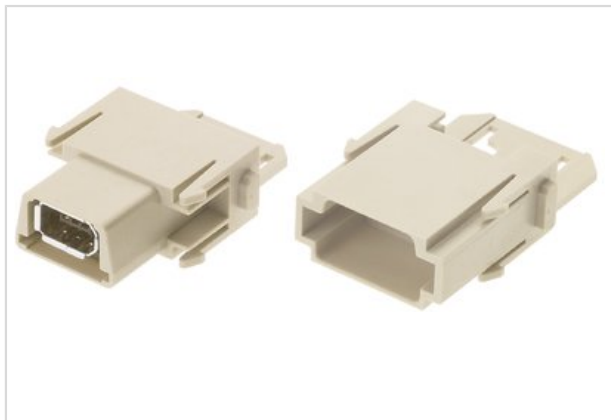

Part number	09 14 001 4711
Specification	Han FireWire modul female gender changer
HARTING eCatalogue	<a href="https://b2b.harting.com/09140014711">https://b2b.harting.com/09140014711</a>

### Identification

Category	Modules
Series	Han-Modular®
Type of module	Han® FireWire module
Description of the module	for patch cable

### Version

Gender	Female
Number of contacts	6

### Technical characteristics

Electrical data acc. to IEC 61984	1 A 50 V 0.8 kV 3
Rated current	1 A
Rated voltage	50 V
Rated impulse voltage	0.8 kV
Pollution degree	3
Insulation resistance	$\geq 10^{10} \Omega$
Limiting temperature	-40 ... +85 °C
Mating cycles	$\geq 500$

### Material properties

Material (insert)	Polycarbonate
Colour (insert)	RAL 7032 (pebble grey)
Material flammability class acc. to UL 94	V-0
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	No
REACH ANNEX XIV substances	No



Pushing Performance

## Material properties

REACH SVHC substances	No
-----------------------	----

## Specifications and approvals

Specifications	EN 60664-1 IEC 61984
----------------	-------------------------

Approvals	DNV GL
-----------	--------

UL / CSA	UL 1977 ECBT2.E235076
----------	-----------------------

## Commercial data

Packaging size	1
----------------	---

Net weight	16.34 g
------------	---------

Country of origin	Germany
-------------------	---------

Customs tariff number	85389099
-----------------------	----------