


## Han RJ45 module, female gender changer

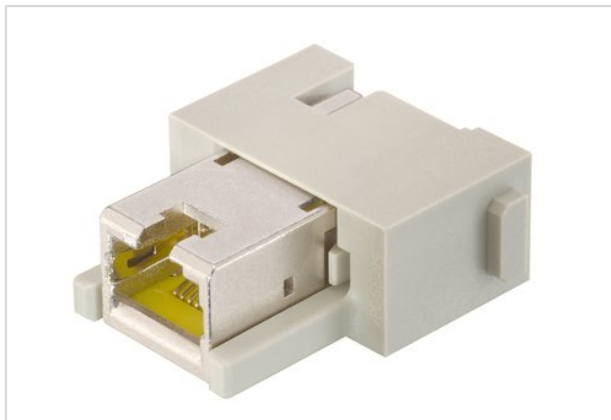

Part number	09 14 001 4721
Specification	Han RJ45 module, female gender changer
HARTING eCatalogue	<a href="https://b2b.harting.com/09140014721">https://b2b.harting.com/09140014721</a>

### Identification

Category	Modules
Series	Han-Modular®
Type of module	Han® RJ45 module
Description of the module	Gender changer for patch cable

### Version

Gender	Female
Number of contacts	8

### Technical characteristics

Electrical data acc. to IEC 61984	1 A 50 V 0.8 kV 3
Rated current	1 A
Rated voltage	50 V
Rated impulse voltage	0.8 kV
Pollution degree	3
Rated voltage acc. to UL	30 V
Insulation resistance	$\geq 10^{10} \Omega$
Limiting temperature	-40 ... +70 °C
Mating cycles	$\geq 500$
Transmission characteristics	Cat. 6 <sub>A</sub> Class E <sub>A</sub> up to 500 MHz

### Material properties

Material (insert)	Polycarbonate Zinc die-cast, nickel-plated
Colour (insert)	RAL 7032 (pebble grey)
Material flammability class acc. to UL 94	V-0
RoHS	compliant
ELV status	compliant



Pushing Performance

## Material properties

China RoHS	e
REACH Annex XVII substances	No
REACH ANNEX XIV substances	No
REACH SVHC substances	No

## Specifications and approvals

Specifications	EN 60664-1 IEC 61984
Approvals	DNV GL
UL / CSA	UL 1977 ECBT2.E235076

## Commercial data

Packaging size	1
Net weight	25.35 g
Country of origin	Germany
Customs tariff number	85389099