


## Han-Snap Carrier, Standard, pivoting

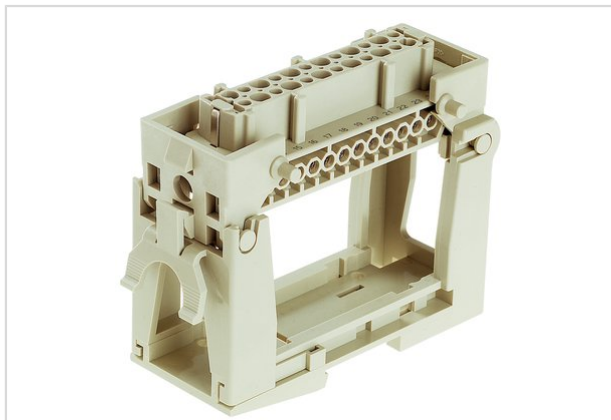

Part number	09 33 000 9801
Specification	Han-Snap Carrier, Standard, pivoting
HARTING eCatalogue	<a href="https://b2b.harting.com/09330009801">https://b2b.harting.com/09330009801</a>

### Identification

Category	Accessories
Series	Han-Snap®
Type of accessory	Insert mounting
Description of the accessory	Swinging for standard inserts

### Technical characteristics

Limiting temperature	-40 ... +125 °C
Tightening torque	0.8 Nm
Retention force	≥450 N On rail

### Material properties

Material (accessories)	Polycarbonate
Colour (accessories)	RAL 7032 (pebble grey)
Material flammability class acc. to UL 94	V-0
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	No
REACH ANNEX XIV substances	No
REACH SVHC substances	No

### Specifications and approvals

Specifications	IEC 60068-2-6 Vibration (sinusoidal) IEC 60068-2-27 Shock
----------------	--

### Commercial data

Packaging size	1
Net weight	95 g
Country of origin	Germany



Pushing Performance

## Commercial data

Customs tariff number	85389099
-----------------------	----------

---