


## Han-Snap Standard Rail Fixing Type 6/10

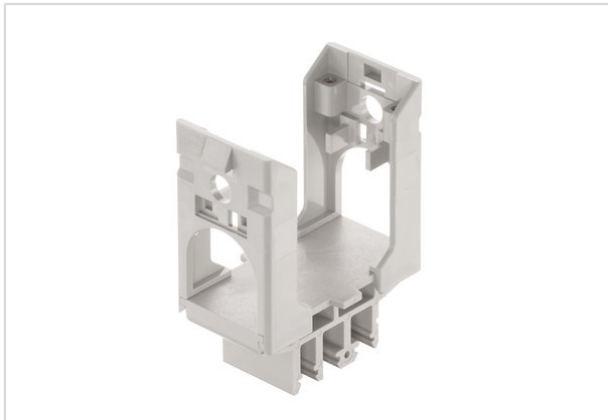

Part number	09 33 000 9988
Specification	Han-Snap Standard Rail Fixing Type 6/10
HARTING eCatalogue	<a href="https://b2b.harting.com/09330009988">https://b2b.harting.com/09330009988</a>
<b>Identification</b>	
Category	Accessories
Series	Han-Snap®
Type of accessory	Insert mounting
Description of the accessory	With carrier element Type 6/10

### Version

Pack contents	2 insert mounting parts 1 carrier element
---------------	--

### Technical characteristics

Limiting temperature	-40 ... +125 °C
Tightening torque	0.8 Nm
Retention force	≥450 N On rail

### Material properties

Material (accessories)	Polycarbonate
Colour (accessories)	RAL 7032 (pebble grey)
Material flammability class acc. to UL 94	V-0
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	No
REACH ANNEX XIV substances	No
REACH SVHC substances	No

### Specifications and approvals

Specifications	IEC 60068-2-6 Vibration (sinusoidal)
----------------	--------------------------------------



Pushing Performance

## Specifications and approvals

IEC 60068-2-27 Shock

## Commercial data

Packaging size	10
Net weight	45.86 g
Country of origin	Germany
Customs tariff number	85389099