


Han-Snap Latching Parts w/o StrainRelief

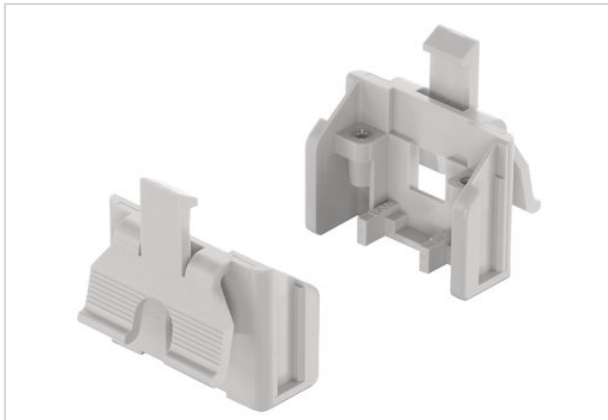

Part number	09 33 000 9987
Specification	Han-Snap Latching Parts w/o StrainRelief
HARTING eCatalogue	https://b2b.harting.com/09330009987

Identification

Category	Accessories
Series	Han-Snap®
Type of accessory	Latching parts

Version

Pack contents	2 latching parts
---------------	------------------

Technical characteristics

Limiting temperature	-40 ... +125 °C
Tightening torque	0.8 Nm
Degree of protection acc. to IEC 60529	IP20
Retention force	200 N Without guiding 300 N With guiding

Material properties

Material (accessories)	Polycarbonate
Colour (accessories)	RAL 7032 (pebble grey)
Material flammability class acc. to UL 94	V-0
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	No
REACH ANNEX XIV substances	No
REACH SVHC substances	No

Specifications and approvals

Specifications	IEC 60068-2-6 Vibration (sinusoidal) IEC 60068-2-27 Shock
----------------	--



Pushing Performance

Commercial data

Packaging size	10
Net weight	17.36 g
Country of origin	Germany
Customs tariff number	85389099