


Han-Yellock 60 carrier hood button slot

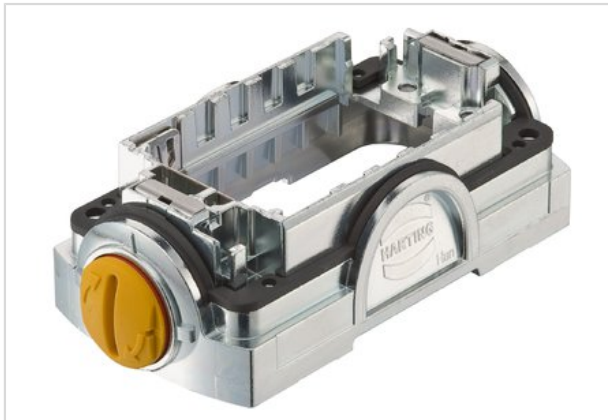

Part number	11 12 600 0110
Specification	Han-Yellock 60 carrier hood button slot
HARTING eCatalogue	https://b2b.harting.com/11126000110

Identification

Category	Hoods/Housings
Series of hoods/housings	Han-Yellock®
Type of hood/housing	Carrier hood
Description of hood/housing	Push button, slot

Version

Locking type	Push button
Size	Han-Yellock® 60
Field of application	Hoods/housings for industrial applications

Technical characteristics

Limiting temperature	-40 ... +125 °C
Un-/locking temperature	-10 ... +85 °C
Mating cycles	≥500
Degree of protection acc. to IEC 60529	IP65 IP67

Material properties

Material (hood/housing)	Aluminium die-cast
Surface (hood/housing)	Passivated
Colour (hood/housing)	Metallic
Material (seal)	NBR
Material (locking)	Polyamide Stainless steel
Colour (locking)	Melon yellow
Material flammability class acc. to UL 94	V-0
RoHS	compliant
ELV status	compliant
China RoHS	e



Pushing Performance

Material properties

REACH Annex XVII substances	No
REACH ANNEX XIV substances	No
REACH SVHC substances	No

Specifications and approvals

Specifications	EN 60664-1 IEC 61984
Approvals	DNV GL

Commercial data

Packaging size	1
Net weight	252.7 g
Country of origin	Germany
Customs tariff number	85389099