

PRODUCT DATASHEET

1906 PIPE ANGLED 550x600

Vintage 1906 Pipe | Indoor industrial design luminaires, vintage style, E27 socket



AREAS OF APPLICATION

- Living areas (living rooms, dining rooms, bedrooms etc.)
- Bars, restaurants

PRODUCT BENEFITS

- Adjustable appearance thanks to use of separate available E27 lamp shapes
- Easy and quick installation

PRODUCT FEATURES

- Reduced industrial design
- Special vintage appearance when combined with 1906 LED or halogen lamps
- Luminaire family for various application areas




TECHNICAL DATA

Electrical data

Operating mode	Mains voltage
Nominal voltage	220...240 V
Mains frequency	50/60 Hz

Dimensions & weight

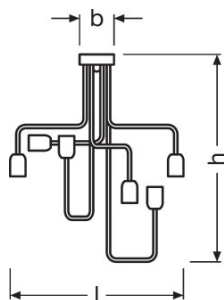

Length	534.0 mm
Width	100.0 mm
Height	610.0 mm
Product weight	1350.00 g

Colors & materials

Body material	Glass
Cover material	Glass

Temperatures & operating conditions

Ambient temperature range	-20...40 °C
----------------------------------	-------------

Additional product data

Product remark	Available from April 2019
-----------------------	---------------------------

Capabilities

Dimmable	No
Type of connection	Terminal
Holder designation	E27

Certificates & standards

Protection class	I
Type of protection	IP20

Standards

CEEACREACH

EQUIPMENT / ACCESSORIES

- No light sources included
- Complete mounting and connecting accessories included

LOGISTICAL DATA

Product code	Packaging unit (Pieces/Unit)	Dimensions (length x width x height)	Gross weight	Volume
4058075217041	Folding carton box 1	173 mm x 573 mm x 693 mm	1926.00 g	68.70 dm ³
4058075217058	Shipping carton box 2	585 mm x 360 mm x 705 mm	5880.00 g	148.47 dm ³

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

DISCLAIMER

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.