

PRODUCT DATASHEET

1906 PIPE TABLE 170x150x400

Vintage 1906 Pipe | Indoor industrial design luminaires, vintage style, E27 socket

AREAS OF APPLICATION

- Living areas (living rooms, dining rooms, bedrooms etc.)
- Bars, restaurants

PRODUCT BENEFITS

- Adjustable appearance thanks to use of separate available E27 lamp shapes
- Easy and quick installation

PRODUCT FEATURES

- Reduced industrial design
- Special vintage appearance when combined with 1906 LED or halogen lamps
- Luminaire family for various application areas




TECHNICAL DATA

Electrical data

Operating mode	Mains voltage
Nominal voltage	220...240 V
Mains frequency	50/60 Hz

Dimensions & weight

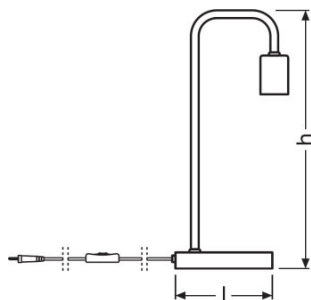

Length	150.0 mm
Height	375.0 mm
Product weight	950.00 g

Colors & materials

Body material	Glass
Cover material	Glass

Temperatures & operating conditions

Ambient temperature range	-20...40 °C
----------------------------------	-------------

Additional product data

Product remark	Available from April 2019
-----------------------	---------------------------

Capabilities

Dimmable	No
Type of connection	Plug, EU
Holder designation	E27

Certificates & standards

Protection class	II
Type of protection	IP20
Standards	CEEACREACH

EQUIPMENT / ACCESSORIES

- No light sources included
- Complete mounting and connecting accessories included

LOGISTICAL DATA

Product code	Packaging unit (Pieces/Unit)	Dimensions (length x width x height)	Gross weight	Volume
4058075217102	Folding carton box 1	190 mm x 190 mm x 472 mm	1141.00 g	17.04 dm ³
4058075217119	Shipping carton box 6	590 mm x 395 mm x 485 mm	9760.00 g	113.03 dm ³

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

DISCLAIMER

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.