

Fittings for metallic conduits with plastic coating

- PCS-FF Fixed Internal Thread, IP54

Fixed internal thread, nickel plated brass.


Features and Benefits

- Two-part fitting of shell and body with external thread
- Provides tight, reliable hold of conduit
- Can be used to couple two conduits together when used with swivel fitting



HeloGuard PCS-FF Fixed Internal Thread.

MATERIAL	Nickel Plated Brass (NPB)
Operating Temperature	-100 °C to +300 °C

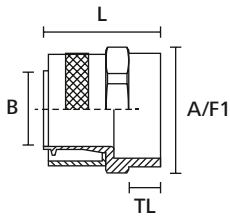

HeloGuard fitting, straight with fixed internal thread

TYPE	Nominal Ø	Thread Size	Min. Bore Size (B)	Length (L)	A/F Body (A/F1)	Thread Length (TL)	Pack Cont.	Colour	Article-No.
PCS16-FF-M20	16	M20	11.5	24.5	22	10.0	10 pcs.	Metal (ML)	166-31300
PCS20-FF-M20	20	M20	15.3	26.0	24	10.0	10 pcs.	Metal (ML)	166-31301
PCS25-FF-M25	25	M25	19.1	30.0	29	12.0	10 pcs.	Metal (ML)	166-31302
PCS32-FF-M32	32	M32	26.2	33.3	36	13.0	10 pcs.	Metal (ML)	166-31303

All dimensions in mm. Subject to technical changes.
Minimum Order Quantity (MOQ) may differ from package content.