



Heat Shrinkable Tubing 3:1 in blister bags

HIS-3 BAG

HIS-3 BAG tubings are useable for insulation and protection of cables and harnesses.

Features and Benefits

- Thin walled and flexible tubing made of cross-linked Polyolefin
- High shrink ratio (3:1) tubing
- Handy, small packaging with 10 pre-cut pieces of 200 mm




HIS-3 BAG available in seven colours and four sizes.



Detailed Information about Heatguns please refer to page 529.

MATERIAL	Polyolefin, cross-linked (PO-X)
Shrink Ratio	3:1
Operating Temperature	-55 °C to +135 °C
Minimum Shrink Temperature	+100 °C
Longitudinal change after shrinkage	-5 % max.
Dielectric Strength	20 kV/mm according to ASTM D 150
Flammability	UL224 VW-1 (except clear)
Specifications	SAE - AMS - DTL-23053/5 Class 1 and 3, SAE - AMS - DTL-23053/5 Class 2 (clear), UL224 125 °C 600V VW-1

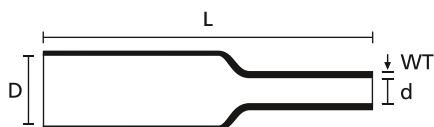

Heat Shrinkable Tubing 3:1

RoHS ✓

TYPE	Supplied Ø D min.	Recov. Ø d max.	Wall (WT)	Length (L)	Pack Cont.	Colour	Article-No.
HIS-3-BAG-1.5/0.5	1.5	0.5	0.45	200.0	10 pcs.	Black (BK)	308-30151
	1.5	0.5	0.45	200.0	10 pcs.	Blue (BU)	308-30161
	1.5	0.5	0.45	200.0	10 pcs.	Brown (BN)	308-30163
	1.5	0.5	0.45	200.0	10 pcs.	Green-Yellow (GNYE)	308-30165
	1.5	0.5	0.45	200.0	10 pcs.	Grey (GY)	308-30162
	1.5	0.5	0.45	200.0	10 pcs.	Red (RD)	308-30160
	1.5	0.5	0.45	200.0	10 pcs.	Transparent (CL)	308-30164
HIS-3-BAG-3/1	3.0	1.0	0.55	200.0	10 pcs.	Black (BK)	308-30310
	3.0	1.0	0.55	200.0	10 pcs.	Blue (BU)	308-30312
	3.0	1.0	0.55	200.0	10 pcs.	Brown (BN)	308-30314
	3.0	1.0	0.55	200.0	10 pcs.	Green-Yellow (GNYE)	308-30316
	3.0	1.0	0.55	200.0	10 pcs.	Grey (GY)	308-30313
	3.0	1.0	0.55	200.0	10 pcs.	Red (RD)	308-30311
	3.0	1.0	0.55	200.0	10 pcs.	Transparent (CL)	308-30315

All dimensions in mm. Subject to technical changes.
Minimum Order Quantity (MOQ) may differ from package content.




For product specific approvals and specifications please refer to the Appendix.



Heat Shrinkable Tubing 3:1 in blister bags

HIS-3 BAG

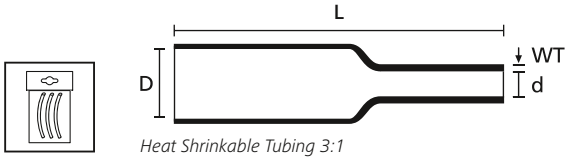

TYPE	Supplied Ø D min.	Recov. Ø d max.	Wall (WT)	Length (L)	Pack Cont.	Colour	Article-No.
HIS-3-BAG-6/2	6.0	2.0	0.65	200.0	10 pcs.	Black (BK)	308-30610
	6.0	2.0	0.65	200.0	10 pcs.	Blue (BU)	308-30612
	6.0	2.0	0.65	200.0	10 pcs.	Brown (BN)	308-30614
	6.0	2.0	0.65	200.0	10 pcs.	Grey (GY)	308-30613
	6.0	2.0	0.65	200.0	10 pcs.	Red (RD)	308-30611
	6.0	2.0	0.65	200.0	10 pcs.	Transparent (CL)	308-30615
	6.0	2.0	0.65	200.0	10 pcs.	Green-Yellow (GNYE)	308-30617
HIS-3-BAG-12/4	12.0	4.0	0.80	200.0	10 pcs.	Black (BK)	308-31210
	12.0	4.0	0.80	200.0	10 pcs.	Blue (BU)	308-31212
	12.0	4.0	0.80	200.0	10 pcs.	Brown (BN)	308-31214
	12.0	4.0	0.80	200.0	10 pcs.	Grey (GY)	308-31213
	12.0	4.0	0.80	200.0	10 pcs.	Red (RD)	308-31211
	12.0	4.0	0.80	200.0	10 pcs.	Transparent (CL)	308-31215
	12.0	4.0	0.80	200.0	10 pcs.	Green-Yellow (GNYE)	308-31217

All dimensions in mm. Subject to technical changes.
Minimum Order Quantity (MOQ) may differ from package content.



For product specific approvals and specifications please refer to the Appendix.