



Bottle Shapes, VG style

Helashrink 150 Series, with rib

Features and Benefits

- Use in conjunction with circular grooved adaptor
- For strain relief and environmental sealing




For Material / Adhesive information please refer to page 244.



150 Series boot recovered onto a connector.



a: Expanded form (supplied)

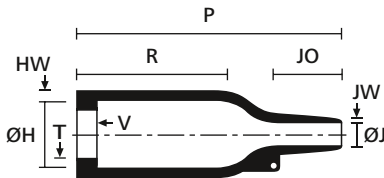

b: Fully recovered form (after heating)



150 Series supplied.

TYPE	ØH min. a	ØH max. b	ØJ min. a	ØJ max. b	P ± 10%	R ± 10%	JO ± 10%	HW ± 20%	JW ± 20%	V max	T ± 20%	Designation as per VG-Norm	Article-No.
152-41-G	24.0	10.5	24.0	6.0	26.0	9.0	10.0	1.6	0.5	3.3	1.0	VG 95343 T06 A 001 A	401-52780
152-42-G	24.0	10.5	24.0	6.0	38.0	21.0	10.0	1.6	0.5	3.3	1.0	VG 95343 T06 B 001 A	401-52880
153-41-G	25.0	14.0	9.0	3.5	40.0	13.0	16.0	1.8	0.5	3.3	1.0	VG 95343 T06 A 002 A	401-53780
153-42-G	25.0	14.0	9.0	3.5	55.0	28.0	16.0	1.8	0.5	3.3	1.0	VG 95343 T06 B 002 A	401-53880
154-41-G	30.0	14.0	30.0	6.0	43.0	20.0	13.0	1.8	1.0	3.3	1.0	VG 95343 T06 A 003 A	401-54780
154-42-G	30.0	14.0	30.0	6.0	55.0	32.0	13.0	1.8	1.0	3.3	1.0	VG 95343 T06 B 003 A	401-54880
155-42-G	31.0	18.0	31.0	7.0	67.0	35.0	18.0	1.8	1.0	3.3	1.0	VG 95343 T06 B 004 A	401-55880
156-41-G	36.0	22.5	36.0	8.5	60.0	22.0	20.0	2.0	1.0	3.3	1.0	VG 95343 T06 A 005 A	401-56780
156-42-G	36.0	22.5	36.0	8.5	80.0	42.0	20.0	2.0	1.0	3.3	1.0	VG 95343 T06 B 005 A	401-56880
157-41-G	43.0	28.0	43.0	10.0	60.0	21.0	20.0	2.2	1.0	3.3	1.7	VG 95343 T06 A 006 A	401-57780
157-42-G	43.0	28.0	43.0	10.0	79.0	41.0	20.0	2.2	1.0	3.3	1.7	VG 95343 T06 B 006 A	401-57880
157-43-G	43.0	28.0	43.0	10.0	99.0	61.0	20.0	2.2	1.0	3.3	1.7	VG 95343 T06 C 001 A	401-57980
158-41-G	60.0	35.0	60.0	16.0	90.0	32.0	38.0	3.2	1.5	3.3	1.7	VG 95343 T06 A 007 A	401-58780
158-42-G	60.0	35.0	60.0	16.0	110.0	52.0	38.0	3.2	1.5	3.3	1.7	VG 95343 T06 B 007 A	401-58880
158-43-G	60.0	35.0	60.0	16.0	130.0	72.0	38.0	3.2	1.5	3.3	1.7	VG 95343 T06 C 002 A	401-58980
159-41-G	66.0	45.0	66.0	17.0	130.0	50.0	50.0	3.8	2.0	3.3	2.0	VG 95343 T06 A 008 A	401-59780
159-42-G	66.0	45.0	66.0	17.0	150.0	70.0	50.0	3.8	2.0	3.3	2.0	VG 95343 T06 B 008 A	401-59880
159-43-G	66.0	45.0	66.0	17.0	171.0	90.0	50.0	3.8	2.0	3.3	2.0	VG 95343 T06 C 003 A	401-59980
160-41-G	82.0	58.0	82.0	27.0	137.0	37.0	62.0	3.8	3.8	3.3	2.0	VG 95343 T06 A 009 A	401-60780
160-42-G	82.0	58.0	82.0	27.0	158.0	58.0	62.0	3.8	3.8	3.3	2.0	VG 95343 T06 B 009 A	401-60880
160-43-G	82.0	58.0	82.0	27.0	213.0	113.0	62.0	3.8	3.8	3.3	2.0	VG 95343 T06 C 004 A	401-60980

All dimensions in mm. Subject to technical changes.



For product specific approvals and specifications please refer to the Appendix.