




Right-Angle Shapes, VG-Style


Helashrink 1100 Series, with rib

Features and Benefits


- Used in conjunction with a circular grooved adaptor
- Provides strain relief and an environmental seal

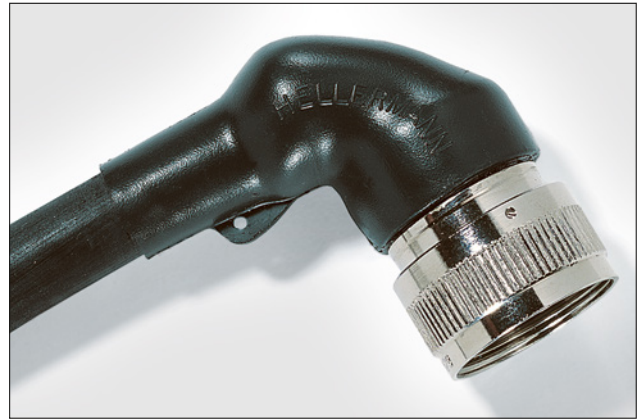

1152-4-G recovered on to a connector.

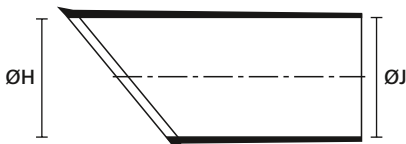

a: Expanded form (supplied)

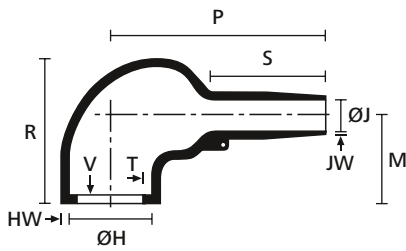

b: Fully recovered form (after heating)



1155-4 supplied.

TYPE	ØH min. a	ØH max. b	ØJ min. a	ØJ max. b	P ± 10%	R ± 10%	HW ± 20%	JW ± 20%	V max	T ± 20%	M nom	S nom	Designation as per VG-Norm	Article-No.
1152-4-G	24.0	10.5	24.0	6.0	26.0	25.0	1.3	0.5	3.3	1.0	19	10.0	VG95343T06E001A	411-52480
1154-4-G	30.0	15.5	30.0	6.0	32.0	27.0	1.5	0.8	3.3	1.0	19	12.0	VG95343T06E002A	411-54480
1155-4-G	31.0	18.0	31.0	7.0	40.0	31.0	1.8	1.0	3.3	1.0	21	15.0	VG95343T06E003A	411-55480
1156-4-G	36.0	22.5	36.0	8.5	46.0	38.0	1.8	1.0	3.3	1.0	26	15.0	VG95343T06E004A	411-56480
1157-4-G	43.0	28.5	43.0	10.0	55.0	45.0	2.0	1.0	3.3	1.7	30	16.0	VG95343T06E005A	411-57480
1158-4-G	60.0	35.0	60.0	16.0	80.0	54.0	3.3	1.5	3.3	1.7	35	30.0	VG95343T06E006A	411-58480
1159-4-G	66.0	45.0	66.0	17.0	108.0	68.0	3.8	2.0	3.3	2.0	42	51.0	VG95343T06E007A	411-59480
1160-4-G	82.0	61.0	82.0	25.0	118.0	84.0	4.0	4.0	3.3	2.0	52	39.0	VG95343T06E008A	411-60480

All dimensions in mm. Subject to technical changes.



For product specific approvals and specifications please refer to the Appendix.