



Bottle Shapes, VG style


Helashrink 170 Series, with rib

Features and Benefits


- Cable strain relief for partially loaded connectors
- Small cable diameters
- Use with our W24 adhesive for excellent chemical resistance



177-1-G as supplied / fully recovered.

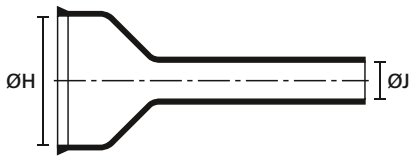

a: Expanded form (supplied)

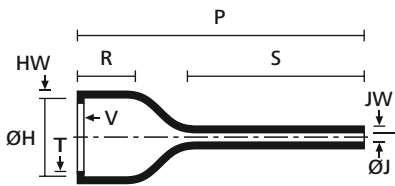

b: Fully recovered form (after heating)

TYPE	ØH min. a	ØH max. b	ØJ min. a	ØJ max. b	P ± 10%	R ± 10%	T ± 20%	HW ± 20%	JW nom.	V max	S nom	Designation as per VG-Norm	Article-No.
176-1-G	19.3	13.0	6.3	2.1	60.0	11.7	1.0	1.5	1.1	3.3	38.0	VG95343T06D011A	401-76180
177-1-G	26.1	19.1	7.6	2.6	74.0	12.2	1.0	1.8	1.1	3.3	45.0	VG95343T06D012A	401-77180
178-1-G	34.2	26.0	9.6	3.1	84.0	12.2	1.0	1.8	1.1	3.3	51.0	VG95343T06D013A	401-78180
179-1-G	43.6	34.1	11.4	3.6	100.0	12.2	1.7	1.8	1.1	3.3	58.0	VG95343T06D014A	401-79180

All dimensions in mm. Subject to technical changes.



For product specific approvals and specifications please refer to the Appendix.