



Carrier Marking System, laser

Helafix HC and HCR Carriers

Marking of cable looms, cables, pipes, transport systems, valves, sensors, for inventory marking on machines or other parts.

Features and Benefits

- Versatile transparent carriers for HFX labels used for temporary or permanent marking
- Fixed in place using T18 series cable ties, screws or rivets (carrier HC06, no rivet hole)
- Protects inserted HFX label against damp, dirt, damage and UV radiation
- Helafix HC supplied as cut lengths in bags, pre-cut and pre-punched rivet hole (carrier HC06 have no punched hole)
- Helafix HCR supplied in continuous tube format and can be cut to size with HCT tool
- Helafix HFX labels designed to fit into HC & HCR carriers




Multi-purpose identification potential: Helafix HC and HCR.



We recommend as suitable labels Helafix HFX, see page 465.

MATERIAL	Polyethylene, UV Resistant (PEUV)
Operating Temperature	-60 °C to +65 °C
Flammability	UL94 HB
Chem. Material Properties	Resistance to UV light, water and a variety of solvents.

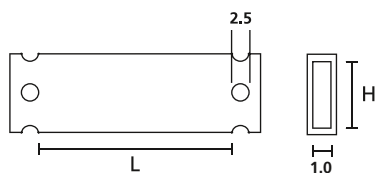

We recommend HCT tool, see page 534.

TYPE	Length (L)	Height (H)	Reel Length	Pack Cont.	Recommended Labels	Application Tool	Article-No.
HCR06	-	7.0	25 m	25 m	-	-	525-07003
HCR09	-	10.0	25 m	25 m	HFX9	HCT1	525-10003
HCR12	-	13.0	25 m	25 m	HFX12	HCT2	525-13003
HCR18	-	19.0	25 m	25 m	-	-	525-19003
HCR24	-	25.0	25 m	25 m	-	-	525-25003
HC06-17	17.5	7.0	-	50 pcs.	-	-	525-07173
HC09-17	17.5	10.0	-	50 pcs.	HFX9-17P	-	525-10173
HC12-17	17.5	13.0	-	50 pcs.	-	-	525-13173
HC06-35	35.0	7.0	-	50 pcs.	-	-	525-07353
HC09-35	35.0	10.0	-	50 pcs.	HFX9-35P	-	525-10353
HC12-35	35.0	13.0	-	50 pcs.	HFX12-35P	-	525-13353
HC18-35	35.0	19.0	-	50 pcs.	-	-	525-19353
HC09-52	52.0	10.0	-	50 pcs.	HFX9-52P	-	525-10523
HC12-52	52.0	13.0	-	50 pcs.	HFX12-52P	-	525-13523
HC18-52	52.0	19.0	-	50 pcs.	-	-	525-19523
HC24-52	52.0	25.0	-	50 pcs.	-	-	525-25523
HC12-70	70.0	13.0	-	50 pcs.	-	-	525-13703
HC18-70	70.0	19.0	-	50 pcs.	-	-	525-19703
HC24-70	70.0	25.0	-	50 pcs.	-	-	525-25703

All dimensions in mm. Subject to technical changes.

Minimum Order Quantity (MOQ) may differ from package content. Other packaging options may also be available.