



## Panel plate labels, thermal transfer

### Helatag 1220 (White)

Panel Labels are durable adhesive labels made from a thick material that is designed to replace traditional engraved plastic plates. The white and silver glossy colours are suited to industrial control panels, switchgear, data racks, and general equipment labeling. Create crisp and clear professional looking labels by printing with TT4000+ or TT430 printers and TT822OUT ribbons.

Simple label design creation is easily achieved using Tagprint Pro.


#### Features and Benefits

- Cost-effective replacement for engraved plastic plates, no need for additional label holder
- High performance adhesive and compressible foam backing ensures optimal adhesion to uneven surfaces if required
- Rounded corners ensure better long term durability of adhesion
- Print high contrast text and barcodes
- Print 'On Site' not order 'Off Site'
- Special sizes and colours are possible on request
- Excellent print performance using TT1220OUT and TT822OUT ribbons
- For outstanding chemical resistance use TT1220OUT
- Print with TT4000+, TT430 for best results
- Easy label design with TagPrint Pro



Panel labels are an ideal replacement for engraved plates.

<b>MATERIAL</b>	Type 1220, Polyester (PET), white (WH)
<b>Operating Temperature</b>	-40 °C to +90 °C
<b>Curing Temperature</b>	from +4 °C
<b>Adhesive</b>	Acrylic
<b>Thickness of Foil (µm)</b>	625 µm
<b>Chem. Material Properties</b>	Excellent resistance to aging, weathering and UV-radiation. Extensive resistance to the influence of chemicals and solvents.
<b>Recommended Ribbon Type</b>	TT1220OUT, TT822OUT

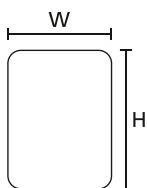

One Step to the Web!



TYPE	Width (W)	Height (H)	Width of Liner (WL)	Labels per Row	Pack Cont.	Colour	Article-No.
TAG13-07TDK1-1220-WH	13.0	7.0	21.0	1	1,000 pcs.	White (WH)	596-00560
TAG22-22TDK1-1220-WH	22.0	22.0	28.0	1	1,000 pcs.	White (WH)	596-00561
TAG27-08TDK1-1220-WH	27.0	8.0	33.0	1	1,000 pcs.	White (WH)	596-00562
TAG27-12.5TDK1-1220-WH	27.0	12.5	33.0	1	1,000 pcs.	White (WH)	596-00558
TAG27-15TDK1-1220-WH	27.0	15.0	33.0	1	1,000 pcs.	White (WH)	596-00563
TAG27-18TDK1-1220-WH	27.0	18.0	33.0	1	1,000 pcs.	White (WH)	596-00564
TAG27-27TDK1-1220-WH	27.0	27.0	33.0	1	1,000 pcs.	White (WH)	596-00565
TAG35-18TDK1-1220-WH	35.0	18.0	41.0	1	1,000 pcs.	White (WH)	596-00566
TAG45-15TDK1-1220-WH	45.0	15.0	51.0	1	1,000 pcs.	White (WH)	596-00567
TAG45-25TDK1-1220-WH	45.0	25.0	51.0	1	1,000 pcs.	White (WH)	596-00568
TAG60-30TDK1-1220-WH	60.0	30.0	66.0	1	500 pcs.	White (WH)	596-00569
TAG90-45TDK1-1220-WH	90.0	45.0	96.0	1	500 pcs.	White (WH)	596-00570
TAG100-30TDK1-1220-WH	100.0	30.0	106.0	1	250 pcs.	White (WH)	596-00571
TAG100-70TDK1-1220-WH	100.0	70.0	106.0	1	250 pcs.	White (WH)	596-00572

All dimensions in mm. Subject to technical changes.

Minimum Order Quantity (MOQ) may differ from package content. Other packaging options may also be available.